



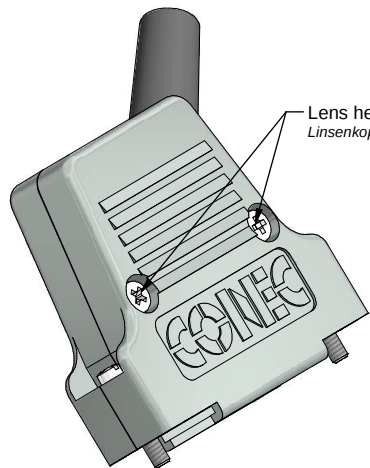

Lens head screw/
Linsenkopfschraube

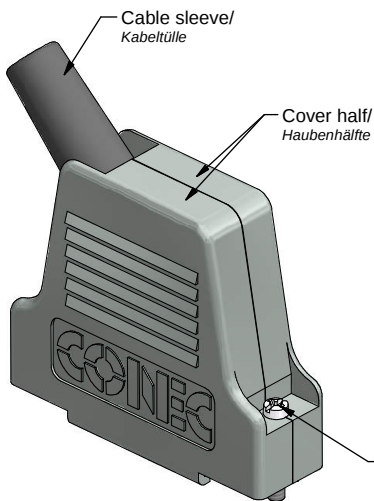

Cable sleeve/
Kabeltülle

Cover half/
Haubenhälfte

Mounting screw/
Befestigungsschraube

b) Technical specification:

Technische Daten:



Temperature range/
Temperaturbereich: - 35 °C ... + 90 °C

Materials/ Werkstoffe:

Cover half/
Haubenhälfte: GD-Zn, Ni
Cable strain relief/
Kabel Zugentlastung: Steel, Ni
Cable sleeve/
Kabeltülle: Rubber
Mounting screw/
Befestigungsschraube: Steel, Ni
Lens head screw/
Linsenkopfschraube: Steel, Ni

Installation specification/ Montagedaten:

Cable outlet/
Kabelausgang: side/Seite

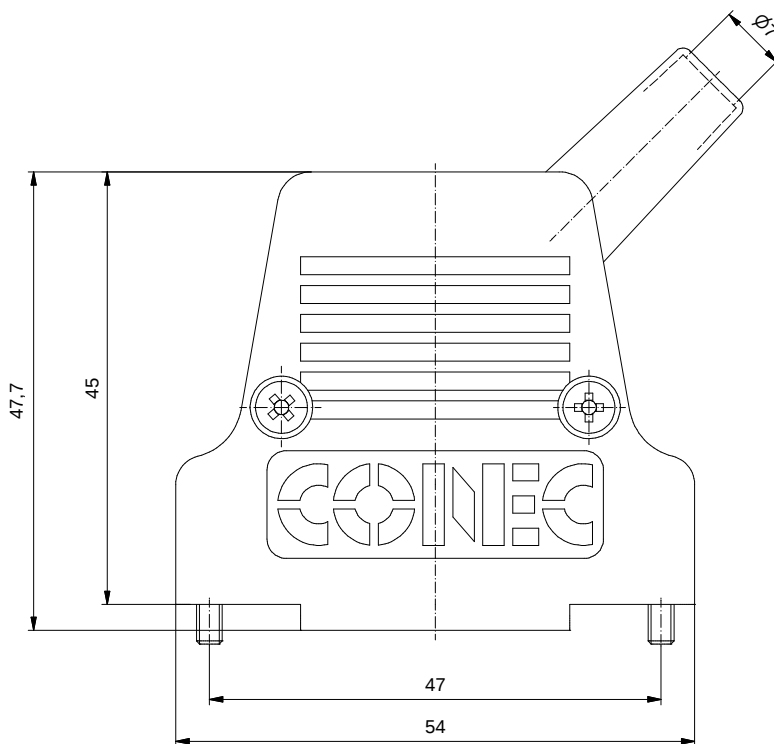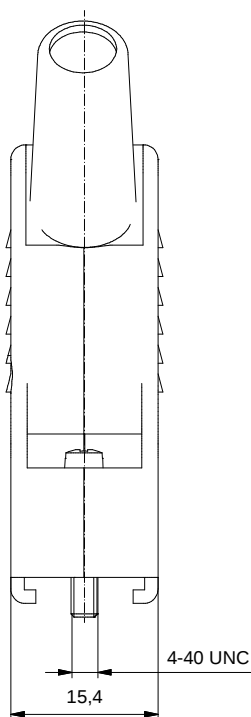

Part no./
Art.-Nr.

165X17579X

				dim. in mm		Full metal hood 25pos. with side cable exit Vollmetallhaube 25pol. mit seitlichem Kabelausgang	
		drawn/ gez.	Date/Datum	Name			
		appd./ gepr.	16.04.2018	Unkrüer			
			17.04.2018	Schmidt			
Index: b Ä7223 16.04.18 L.U.	Scale/Maßstab: 2:1				dwg no / Z.-nr.:	16K1A4044	DIN- A3
Status: InBearbeitung							
RoHS compliant/ konform							1 / 1