


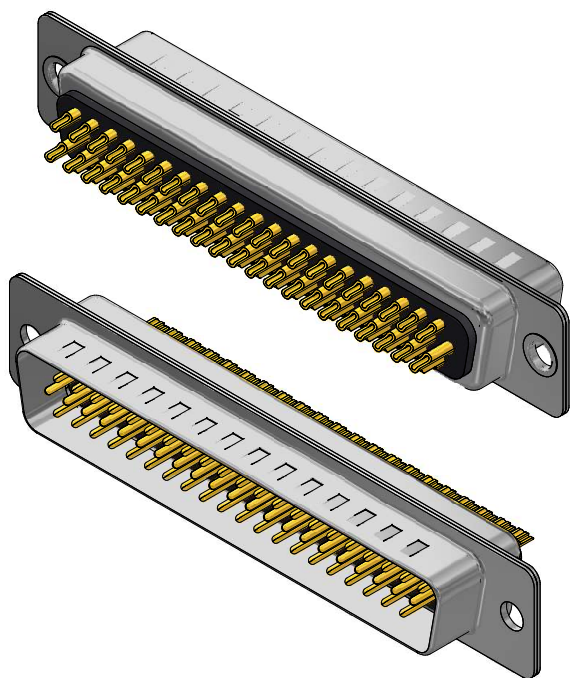

Technical specification/




Technische Daten:

Working voltage/ Betriebsspannung:	60 V AC/DC
Insulation resistance/ Isolationswiderstand:	min. 3000 MOhm
Dielectric withstanding voltage/ Spannungsfestigkeit:	1000 V AC / minute
Operating temperature/ Betriebstemperatur:	- 55 °C ... + 105 °C
Current rating/ Strombelastbarkeit:	3 A
Contact Resistance/ Durchgangswiderstand:	max. 15 mOhm

Materials/

Werkstoffe:

Contact/ Kontakt:	Cu alloy, Underplate/ 50 µin Nickel Beschichtung: Contact area/ Kontaktbereich:	Gold flash
	Solder tails area/ Lötbereich:	Gold flash
Shell/ Gehäuse:	Steel, Nickel plated	
Rivet, Boardlock/ Befestigungsniet:	Copper alloy	
Insulator/ Isolierkörper:	Thermal plastic UL 94 V-0	

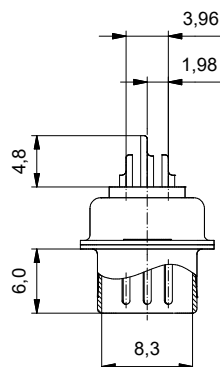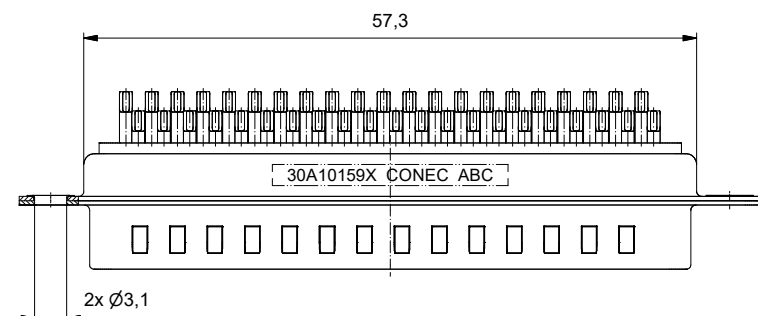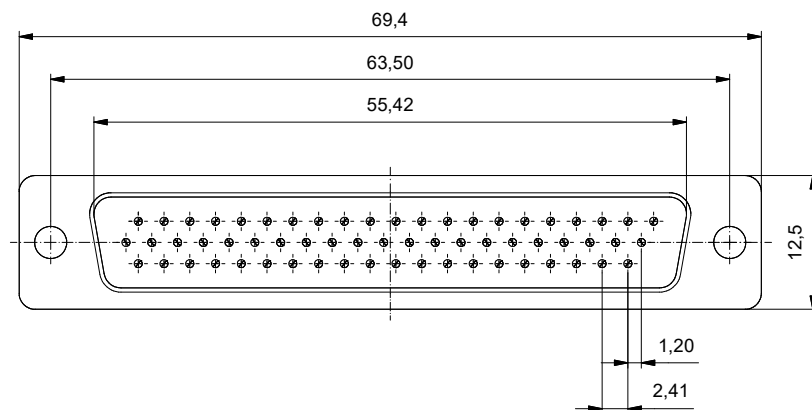

Part no. / Part marked/
Art.-Nr. / Bedruckung:

301A10159X

dim. in mm		D-SUB HD Male 62pos. solder cup stamped contacts D-SUB HD Stiftleiste 62pol. Lötkehlch gestanzte Kontakte	
general tolerance/ Allgemeintoleranz:	0, ±0,5 0, ±0,3 00 ±0,2	Date/Datum 04.07.2022 appd./ gepr.	Name Bub Lehmekühler
Index: a Original	Scale/ Maßstab: 2:1	dwg no / Z.-nr.:	16K1A3977
RoHS compliant/ konform			DIN-A3 1 / 1