



Technical specification/




Technische Daten:

Working voltage/ Betriebsspannung:	60 V AC/DC
Insulation resistance/ Isolationswiderstand:	min. 3000 MOhm
Dielectric withstanding voltage/ Spannungsfestigkeit:	1000 V AC / minute
Operating temperature/ Betriebstemperatur:	- 55 °C ... + 105 °C
Current rating/ Strombelastbarkeit:	3 A
Contact Resistance/ Durchgangswiderstand:	max. 15 mOhm

Materials/

 
Werkstoffe:

Contact/ Kontakt:	Cu alloy, Au over Ni Plating/ Beschichtung:	50 µin Nickel
	Contact Area/ Kontaktbereich:	Gold flash
	Solder Tails Area/ Lötbereich:	Gold flash
Shell/ Gehäuse:	Steel, Nickel plated	
Rivet, Boardlock/ Befestigungsniet:	Copper Alloy	
Insulator/ Isolierkörper:	Thermal Plastic UL 94 V-0	

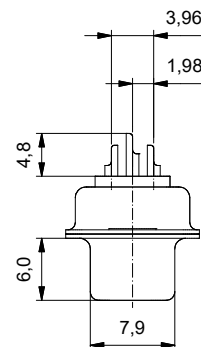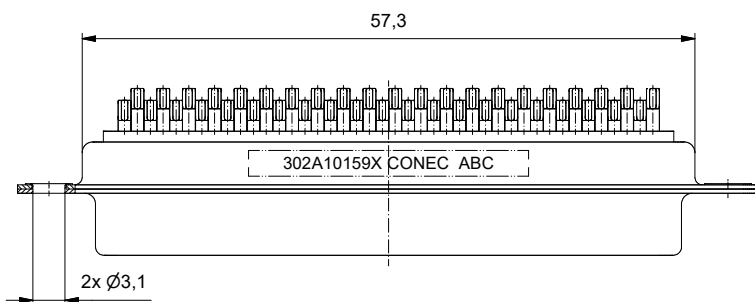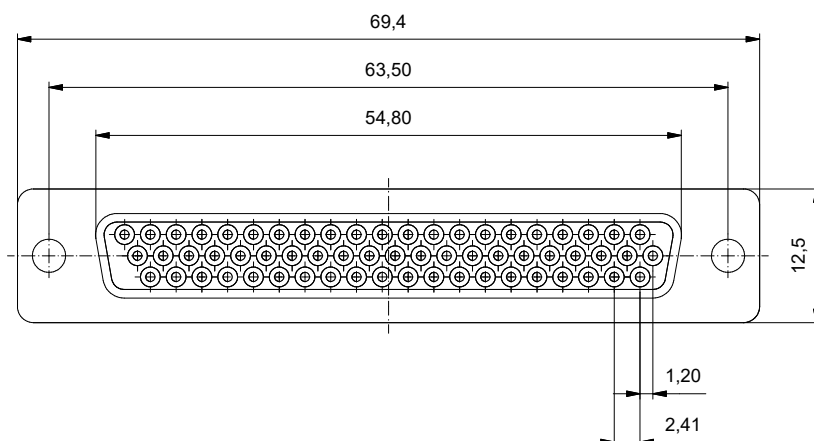

Part no. / Part marked/
Art.-Nr. / Bedruckung:

302A10159X

				dim. in mm		D-SUB HD Female 62pos. solder cup stamped contacts	
general tolerance/ <i>Allgemeintoleranz:</i>	0, ±0.5 ,0 ±0.3 ,00 ±0.2	Date/ <i>Datum</i>		Name		<i>D-SUB HD Buchsenleiste 62pol. Lötkelech gestanzte Kontakte</i>	
		drawn/ <i>gez.</i>		04.07.2022 Bub			
		appd./ <i>gepr.</i>		22.08.2022 Lehmenkühler			
Index: a Original	scale/ <i>Maßstab:</i> 2:1			dwg no / <i>Z.-nr.:</i>		16K1A4315	DIN- A3
RoHS compliant/ <i>konform</i>							1 / 1