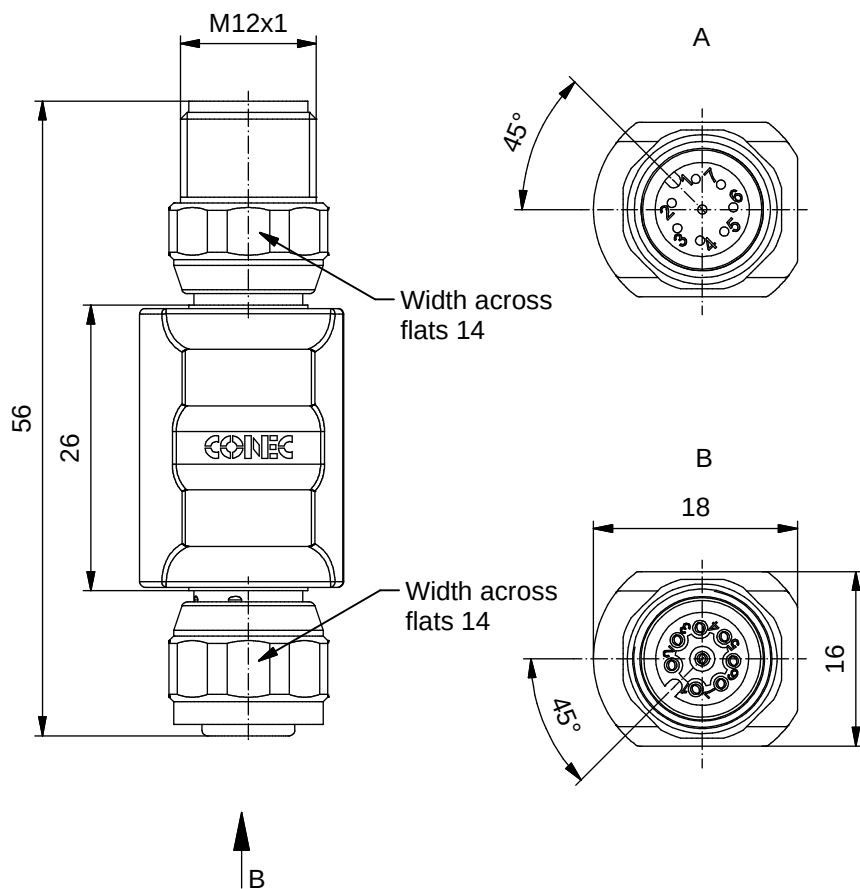


Technical specification:

Rated voltage: IEC 61076-2-101	30 V
Current rating: IEC 61076-2-101	2 A at 40°C
Insulation resistance: IEC 60512	>=100 MΩ
Pollution degree: IEC 60664-1	3/2
Degree of protection: IEC 60529	IP 67, in mated condition
Temperature range:	-30°C ... +80°C
Mating cycles: IEC 60512-9a	>=100

Materials:

Contact:	CuZn
Contact plating:	Nickel, gold plated
Contact carrier:	PA, UL 94
Sealing:	FPM
Coupling nut/ screw:	1.4404 stainless steel
Moulding body:	TPU, UL 94, grey

Installation specification:

Recommended torque:	0,6 Nm
Conec installation tool:	Torque wrench: 36-000200 Insert across flats 14: 36-000370

Contact assignment:


1	1
2	2
3	3
4	4
5	5
6	6
7	7
8	8

Part no:	Description:
43-05149	SAL-12-TSE8-TKE8

DO NOT ALTER CAD DRAWING BY HAND

Directive 2002/95/EC RoHS compliant

	date	name
	drawn 23.10.12	Gitinow
	appd. 23.10.12	Fromm
general tolerance:	0 ± 0,50mm	
	0,0 ± 0,25mm	
	0,00 ± 0,10mm	
THIS DRAWING MAY NOT BE COPIED OR REPRODUCED IN ANY WAY, AND MAY NOT BE PASSED ON TO A THIRD PARTY WITHOUT WRITTEN PERMISSION. OWNERSHIP AND COPYRIGHT OF CONEC GmbH		

 

dim. in mm

CONEC®

title:	Adapter, male connector M12x1 - female connector M12x1 stainless steel
dwg no:	43K1A1782
part no:	see table