
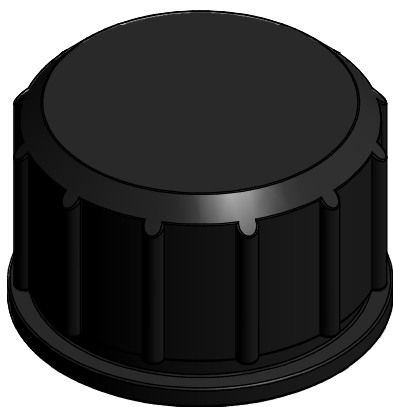
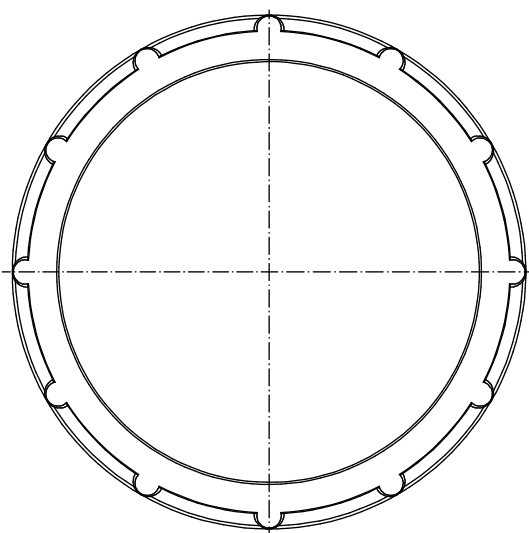


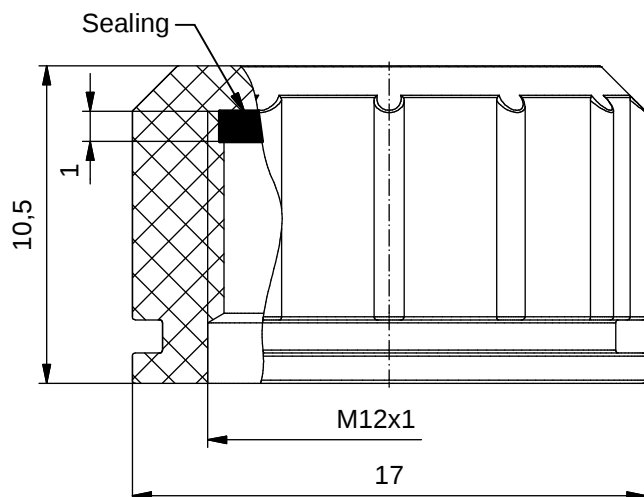

Technical specification:

Degree of protection: IP 67, in mated condition
IEC 60529

Temperature range: -30°C ... +120°C

Materials:

 
Protecting cap: PA GF

Sealing: FPM black

Installation specification:

Recommended torque: 0,6 Nm

Part no:	Description:	Colour:
43-16213	Protecting cap M12x1 male socket	black
43-15753	Protecting cap M12x1 male socket	ivory

DO NOT ALTER CAD DRAWING BY HAND RoHS & REACH compliant	Index: a 27.10.14 Mkf. Ä5406 Part 43-15753 added			 dim. in mm		title: Protecting cap M12x1, male socket	
				date	name		
	tolerance of cable:			drawn	30.10.12	Kniesburgers	dwg no:
				appd.	31.10.12	Franz	
	general tolerance: 0 ± 0,50mm 0,0 ± 0,25mm 0,00 ± 0,10mm					43K1A1798	
	THIS DRAWING MAY NOT BE COPIED OR REPRODUCED IN ANY WAY, AND MAY NOT BE PASSED ON TO A THIRD PARTY WITHOUT WRITTEN PERMISSION. OWNERSHIP AND COPYRIGHT OF CONEC GmbH						
					part no: see table		