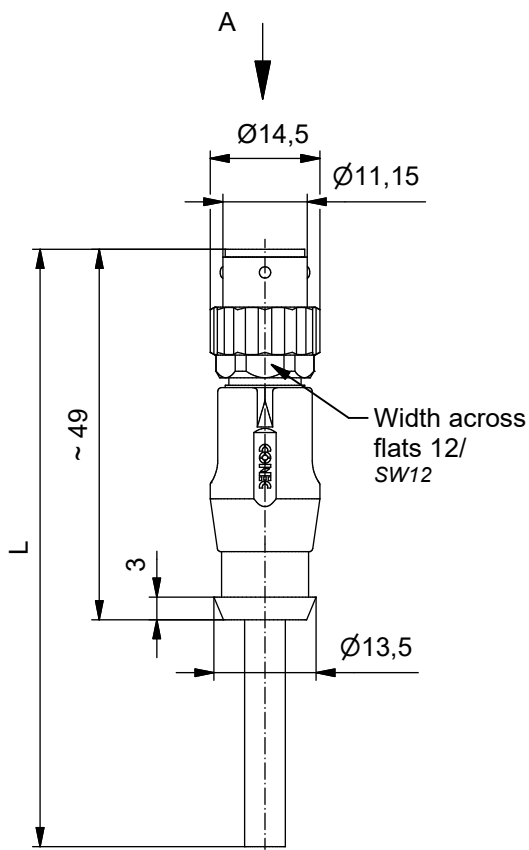


Contact assignment/ Kontaktbelegung:

1	brown/ braun
2	white/ weiß
3	blue/ blau
4	black/ schwarz
5	grey/ grau

Shielding coupling screw/
Schirmauflage Überwurfschraube

Technical specification/

Technische Daten:

Rated Voltage/ Bemessungsspannung: IEC 61076-2-101	60 V AC / 60 V DC
Current rating/ Strombelastbarkeit: IEC 61076-2-101	4 A at/ bei 40 °C
Insulation resistance/ Isolationswiderstand: IEC 60512	>=100 MΩ
Pollution degree/ Verschmutzungsgrad: IEC 60664-1	3/2
Degree of protection/ Schutzart: IEC 60529	IP 65, IP 67, IP 69K, in locked condition/ im verriegelten Zustand
Temperature range/ Umgebungstemperatur: ICE 60664-1	-30 °C ... +80 °C
Mating cycles/ Steckzyklen: IEC 60512-9a	>=100

Cable specification/

Kabeleigenschaften:

Temperatur range/ Umgebungstemperatur:	-30 °C ... +80 °C
---	-------------------

Materials/


Werkstoffe:

Contact/ Kontakt:	CuZn, Ni b / Au 0,2 gal.
Contact carrier/ Kontaktträger:	PA, UL 94 V-0
Coupling screw/ Überwurfschraube:	CuZn, Ni
Moulding body/ Griffkörper:	TPU, UL 94 HB black/ schwarz

Optional installation specification/

Optionale Montageangaben:

Conec	Torque wrench/ Drehmoment-Schlüssel:
Installation tool/ Montagewerkzeug:	36-000200 Insert across flats 12/ Steckeinsatz SW12: 36-000470

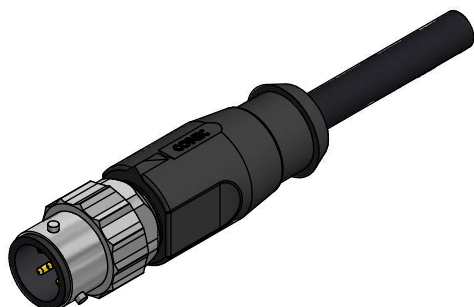


Part no/ Art.-Nr.:	Description/ Beschreibung:	Length L/ Länge L:	Cable/ Kabel:
43-23145	SAL - B12S - RS5.1 - 0,3 / G2 / A1002	0,3 m	TPU, UL 20549, black/ schwarz, 5 x 0,25 mm ² , Li9YC11Y Cable/ Kabel: 781-G22500
43-23065	SAL - B12S - RS5.1 - 2 / G2 / A1002	2 m	
43-23066	SAL - B12S - RS5.1 - 3 / G2 / A1002	3 m	
43-23067	SAL - B12S - RS5.1 - 5 / G2 / A1002	5 m	
43-23068	SAL - B12S - RS5.1 - 10 / G2 / A1002	10 m	
43-xxxxx	SAL - B12S - RS5.1 - ... / G2 / A1002	x	

tolerance of cable/
 Kabeltoleranz:

L <= 4 m: L + 40 mm
 L > 4 m: L + 1 %

general tolerance/
 Allgmeintoleranz:

 0 ± 0,50 mm
 0,0 ± 0,25 mm
 0,00 ± 0,10 mm
 * ± 5°



dim. in mm

	Date/Datum	Name
drawn/ gez.	04.02.2020	Schmidt
appd./ gepr.	06.02.2020	Fischer

Bayonet 12 male connector, axial,
 360° - shielding
 Bajonett 12 Stecker, axial,
 360° - Schirmung

Index: b Ä21-0231 24.09.2021 ABU

scale/Maßstab:
 1:1
 (1,5:1)

CONEC®

dwg no /
 Z.-nr.:

43K1A4658

DIN-
 A4

RoHS compliant/ konform

1 / 1