


216EC4W

Industrial Connector

2CMA101118R1000

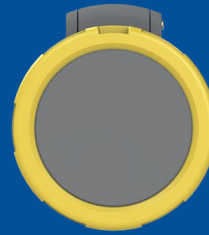

Industrial Connectors, 2P+E, 16A, 100 ... 130 V Clock
Position Of Grounding Contact 4 hour Color code Yellow

GENERAL

Product Name	Industrial Connector
Product ID	2CMA101118R1000
Function	Connector
EAN	73926911181
Catalog Description	Industrial Connectors, 2P+E, 16A, 100 ... 130 V
Country of Origin	Czech Republic (CZ)
E-Number Finland	
E-Number Norway	
E-Number Sweden	
Standards	IEC 60309-1, -2
RoHS Status	Following EU Directive 2011/65/EU

TECHNICAL

Product Main Type	EC
Color	Yellow
Number of Poles	3
Clock Position	4Hour
Rated Current	16 ampere
Rated Voltage	100 ... 130 volt
Frequency	50 hertz 60 hertz
Degree of Protection	IP67
Cable Cross-Section	1...2.5 mm ²
Housing Material	Plastic (PA)
Plug Angle	Straight
Product Group	Easy&Safe

DIMENSIONS

Product Net Width	73 millimetre
Product Net Height	73 millimetre
Product Net Length	146 millimetre
Product Net Depth	146 millimetre
Product Net Weight	0.17 kilogram

PACKAGING

Package Width	310 millimetre
Package Height	147 millimetre
Package Gross Weight	1.7 kilogram
Package Length	140 millimetre
Package Units	box 10 piece