


316EC6W

Industrial Connector

2CMA101127R1000

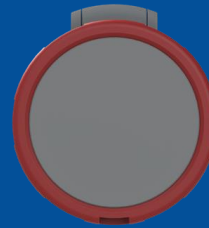

Industrial Connectors, 3P+E, 16A, 380 ... 415 V Clock
Position Of Grounding Contact 6 hour Color code Red

GENERAL

Product Name	Industrial Connector
Product ID	2CMA101127R1000
Function	Connector
EAN	73926911273
Catalog Description	Industrial Connectors, 3P+E, 16A, 380 ... 415 V
Country of Origin	Czech Republic (CZ)
E-Number Finland	2420114
E-Number Norway	1540726
E-Number Sweden	E2416316
Standards	IEC 60309-1, -2
RoHS Status	Following EU Directive 2011/65/EU

TECHNICAL

Product Main Type	EC
Color	Red
Number of Poles	4
Clock Position	6Hour
Rated Current	16 ampere
Rated Voltage	380 ... 415 volt
Frequency	50 hertz 60 hertz
Degree of Protection	IP67
Cable Cross-Section	1...2.5 mm ²
Housing Material	Plastic (PA)
Plug Angle	Straight
Product Group	Easy&Safe

DIMENSIONS

Product Net Width	81 millimetre
Product Net Height	81 millimetre
Product Net Length	169 millimetre
Product Net Depth	169 millimetre
Product Net Weight	0.23 kilogram

PACKAGING

Package Width	355 millimetre
Package Height	169 millimetre
Package Gross Weight	2.3 kilogram
Package Length	150 millimetre
Package Units	box 10 piece