


363ERT6

Wall mounted socket

2CMA101890R1000

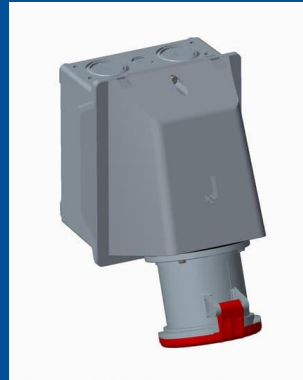

Wall mounted socket, 3P+E, IP44, 63 A, 380 ... 415 V,
Housing in plastic (PBT). Cable entry with knock-outs 2 x
Ø29/37 + 1 x Ø23 on top. 1 x Ø29 + 1 x Ø 23 from
bottom. Cable area 6...25 mm²

GENERAL

Product Name	Wall mounted socket
Product ID	2CMA101890R1000
Function	Wall mounted socket
EAN	739269186
Catalog Description	Socket outlet for wall mounting, IP44, 3P+E, 63 A, 380 ... 415 V
Country of Origin	Czech Republic (CZ)
E-Number Finland	
E-Number Norway	
E-Number Sweden	2418155
Standards	IEC 60309-1, -2
RoHS Status	Following EU Directive 2011/65/EU

DIMENSIONS

Product Net Width	149 millimetre
Product Net Height	214 millimetre
Product Net Length	255 millimetre
Product Net Depth	255 millimetre
Product Net Weight	1.4 kilogram

TECHNICAL

Product Main Type	ERT
Color	Red
Number of Poles	4
Clock Position	6Hour
Rated Current	63 ampere
Rated Voltage	380 ... 415 volt
Frequency	50 hertz 60 hertz
Degree of Protection	IP44
Cable Cross-Section	4...16 mm ²
Housing Material	Thermoplastic (PBT)
Plug Angle	
Product Group	Easy&Safe

PACKAGING

Package Width	225 millimetre
Package Height	155 millimetre
Package Gross Weight	1.4 kilogram
Package Length	265 millimetre
Package Units	box 1 piece