


416ERU6W

# Panel mounted socket

## 2CMA101302R1000

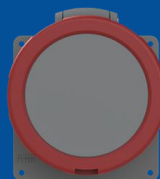

Panel mounted socket outlet, 3P+N+E, IP67, 16 A, 346 ...  
415 V

## GENERAL

|                     |                                                           |
|---------------------|-----------------------------------------------------------|
| Product Name        | Panel mounted socket                                      |
| Product ID          | 2CMA101302R1000                                           |
| Function            | Panel mounted socket                                      |
| EAN                 | 739269124                                                 |
| Catalog Description | Panel mounted socket outlets, 3P+N+E, 16 A, 346 ... 415 V |
| Country of Origin   | Czech Republic (CZ)                                       |
| E-Number Finland    | 2420137                                                   |
| E-Number Norway     |                                                           |
| E-Number Sweden     | E2417697                                                  |
| Standards           | IEC 60309-1, -2                                           |
| RoHS Status         | Following EU Directive 2011/65/EU                         |

## TECHNICAL

|                      |                          |
|----------------------|--------------------------|
| Product Main Type    | ERU                      |
| Color                | Red                      |
| Number of Poles      | 5                        |
| Clock Position       | 6Hour                    |
| Rated Current        | 16 ampere                |
| Rated Voltage        | 200/346 ... 240/415 volt |
| Frequency            | 50 hertz 60 hertz        |
| Degree of Protection | IP67                     |
| Cable Cross-Section  | 1...2.5 mm <sup>2</sup>  |
| Housing Material     | Plastic (PA)             |
| Plug Angle           | Straight                 |
| Product Group        | Easy&Safe                |

## DIMENSIONS

|                    |               |
|--------------------|---------------|
| Product Net Width  | 85 millimetre |
| Product Net Height | 99 millimetre |
| Product Net Length | 84 millimetre |
| Product Net Depth  | 84 millimetre |
| Product Net Weight | 0.21 kilogram |

## PACKAGING

|                      |                |
|----------------------|----------------|
| Package Width        | 74 millimetre  |
| Package Height       | 442 millimetre |
| Package Gross Weight | 2.1 kilogram   |
| Package Length       | 187 millimetre |
| Package Units        | box 10 piece   |