


232ERU6W

Panel mounted socket

2CMA101308R1000

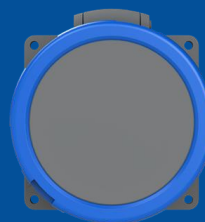

Panel mounted socket outlet, 2P+E, 32A, 200 ... 250 V Clock
Position Of Grounding Contact 6 hour Color code Blue

GENERAL

Product Name	Panel mounted socket
Product ID	2CMA101308R1000
Function	Panel mounted socket
EAN	739269186
Catalog Description	Panel mounted socket outlets, 2P+E, 32A, 200 ... 250 V
Country of Origin	Czech Republic (CZ)
E-Number Finland	2420238
E-Number Norway	
E-Number Sweden	E2417703
Standards	IEC 60309-1, -2
RoHS Status	Following EU Directive 2011/65/EU

TECHNICAL

Product Main Type	ERU
Color	Blue
Number of Poles	3
Clock Position	6Hour
Rated Current	32 ampere
Rated Voltage	200 ... 250 volt
Frequency	50 hertz 60 hertz
Degree of Protection	IP67
Cable Cross-Section	2.5...6 mm ²
Housing Material	Plastic (PA)
Plug Angle	Straight
Product Group	Easy&Safe

DIMENSIONS

Product Net Width	85 millimetre
Product Net Height	98 millimetre
Product Net Length	101 millimetre
Product Net Depth	101 millimetre
Product Net Weight	0.22 kilogram

PACKAGING

Package Width	94 millimetre
Package Height	442 millimetre
Package Gross Weight	2.2 kilogram
Package Length	192 millimetre
Package Units	box 10 piece