


363P7

Industrial Plug

2CMA166754R1000

Plug, earthing sleeve position 7h, rated current 63A, IP44 splashproof, 3-poles+earth, frequency 50-60 Hz, color code Black

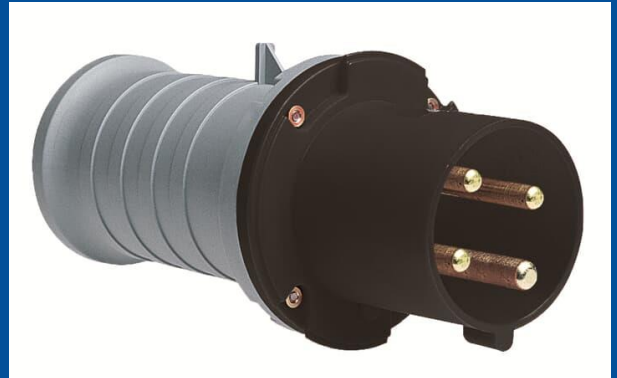

GENERAL

Product Name	Industrial Plug
Product ID	2CMA166754R1000
Function	Plug
EAN	7392696667548
Catalog Description	Plug, 7h, 63A, IP44, 3P+E
Country of Origin	Czech Republic (CZ)
E-Number Finland	2421624
E-Number Norway	1565175
E-Number Sweden	E2416227
Standards	IEC 60309-1, -2
RoHS Status	Following EU Directive 2011/65/EU

TECHNICAL

Product Main Type	TP
Color	Black
Number of Poles	4
Clock Position	7Hour
Rated Current	63 ampere
Rated Voltage	480 ... 500 volt
Frequency	50 hertz 60 hertz
Degree of Protection	IP44
Cable Cross-Section	4...16 mm ²
Housing Material	Thermoplastic (PBT)
Plug Angle	Straight
Product Group	Tough&Safe

DIMENSIONS

Product Net Width	103 millimetre
Product Net Height	103 millimetre
Product Net Length	215 millimetre
Product Net Depth	215 millimetre
Product Net Weight	0.64 kilogram

PACKAGING

Package Width	114 millimetre
Package Height	230 millimetre
Package Gross Weight	0.72 kilogram
Package Length	114 millimetre
Package Units	box 1 piece