


363C9W

Industrial Connector

2CMA166898R1000

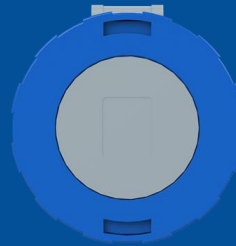

Connector, earthing sleeve position 9h, rated current 63A, IP67 watertight, 3-poles+earth, frequency 50-60 Hz, color code Blue

GENERAL

Product Name	Industrial Connector
Product ID	2CMA166898R1000
Function	Connector
EAN	7392696668989
Catalog Description	Connector, 9h, 63A, IP67, 3P+E
Country of Origin	Czech Republic (CZ)
E-Number Finland	2416414
E-Number Norway	2416414
E-Number Sweden	E2416414
Standards	IEC 60309-1, -2
RoHS Status	Following EU Directive 2011/65/EU

TECHNICAL

Product Main Type	TC
Color	Blue
Number of Poles	4
Clock Position	9Hour
Rated Current	63 ampere
Rated Voltage	200 ... 250 volt
Frequency	50 hertz 60 hertz
Degree of Protection	IP67 IP69
Cable Cross-Section	4...16 mm ²
Housing Material	Thermoplastic (PBT)
Plug Angle	Straight
Product Group	Tough&Safe

DIMENSIONS

Product Net Width	108 millimetre
Product Net Height	112 millimetre
Product Net Length	286 millimetre
Product Net Depth	286 millimetre
Product Net Weight	0.83 kilogram

PACKAGING

Package Width	138 millimetre
Package Height	345 millimetre
Package Gross Weight	0.83 kilogram
Package Length	158 millimetre
Package Units	box 1 piece