


3125P9W

Industrial Plug

2CMA166820R1000

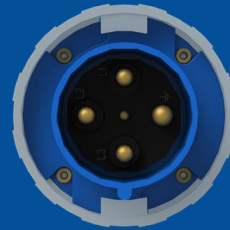

Plug, earthing sleeve position 9h, rated current 125A, IP67 watertight, 3-poles+earth, frequency 50-60 Hz, color code Blue

GENERAL

Product Name	Industrial Plug
Product ID	2CMA166820R1000
Function	Plug
EAN	73926966680
Catalog Description	Plug, 9h, 125A, IP67, 3P+E
Country of Origin	Czech Republic (CZ)
E-Number Finland	2416307
E-Number Norway	2416307
E-Number Sweden	E2416307
Standards	IEC 60309-1, -2
RoHS Status	Following EU Directive 2011/65/EU

TECHNICAL

Product Main Type	TP
Color	Blue
Number of Poles	4
Clock Position	9Hour
Rated Current	125 ampere
Rated Voltage	200 ... 250 volt
Frequency	50 hertz 60 hertz
Degree of Protection	IP67 IP69
Cable Cross-Section	16...50 mm ²
Housing Material	Thermoplastic (PBT)
Plug Angle	Straight
Product Group	Tough&Safe

DIMENSIONS

Product Net Width	127 millimetre
Product Net Height	127 millimetre
Product Net Length	312 millimetre
Product Net Depth	312 millimetre
Product Net Weight	1.43 kilogram

PACKAGING

Package Width	138 millimetre
Package Height	345 millimetre
Package Gross Weight	1.54 kilogram
Package Length	158 millimetre
Package Units	box 1 piece