


363BU11W

Panel mounted inlet

2CMA168112R1000

Inlet, panel mounting, earthing sleeve position 11h, rated current 63A, IP67 watertight, unified flange, straight, 3-poles+earth, frequency 60 Hz, color code Red

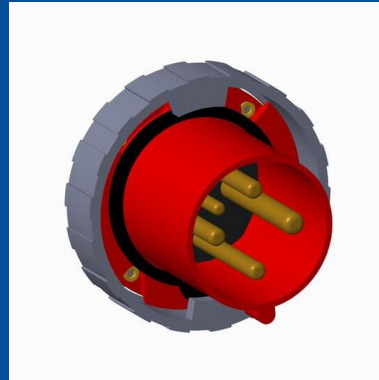

GENERAL

Product Name	Panel mounted inlet
Product ID	2CMA168112R1000
Function	Inlet, panel mounting, unified flange, straight
EAN	7392696681124
Catalog Description	Inlet, panel mounting, 11h, 63A, IP67, unified flange, straight, 3P+E
Country of Origin	Czech Republic (CZ)
E-Number Finland	2417413
E-Number Norway	2417413
E-Number Sweden	2417413
Standards	IEC 60309-1, -2
RoHS Status	Following EU Directive 2011/65/EU

DIMENSIONS

Product Net Width	114 millimetre
Product Net Height	114 millimetre
Product Net Length	126 millimetre
Product Net Depth	126 millimetre
Product Net Weight	0.55 kilogram

TECHNICAL

Product Main Type	TBU
Color	Red
Number of Poles	4
Clock Position	11Hour
Rated Current	63 ampere
Rated Voltage	440 ... 460 volt
Frequency	60 hertz
Degree of Protection	IP67 IP69
Cable Cross-Section	6...25 mm ²
Housing Material	Thermoplastic (PBT)
Plug Angle	Straight
Product Group	Tough&Safe

PACKAGING

Package Width	112 millimetre
Package Height	139 millimetre
Package Gross Weight	0.55 kilogram
Package Length	112 millimetre
Package Units	box 1 piece