

ONPOW39系列蜂鸣器
Series Buzzer

ALL NEW


Φ16~19mm安装孔金属超平头部防水闪光蜂鸣器
Φ16~19mm mounting hole metal ultra-flat head waterproof flash buzzer



- 超平金属头部设计，时尚轻薄
Ultra-flat metal head design, fashionable and lightweight



- 环形+侧面双发光，指示更清晰
Ring + side double light, clearer indication

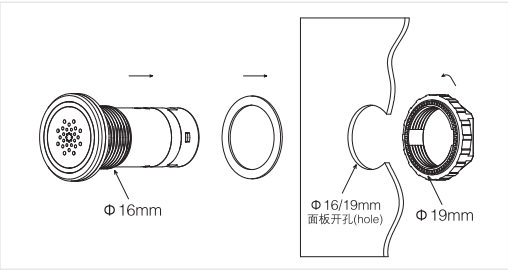

- 通过螺母变径，实现Φ16/Φ19mm通用
Through the nut diameter reduction, it can be used for Φ16/Φ19mm



- 底座采用优质阻燃尼龙材质，阻燃等级可达V0
The base is made of flame retardant nylon, with a flame retardant grade of V0

性能特征 Performance characteristic

工作环境温度 Operating temperature	-20℃~+50℃,海拔 < 2000m -20℃~+50℃,Altitude < 2000m	工作环境湿度 Operating humidity	35~85 % RH(无结露 Non condensing)
额定使用电压 Rated operating voltage	12VDC ± 10%, 24VDC ± 10%	额定绝缘电压 Rated insulation voltage	250VAC
工频耐压 Power frequency withstand voltage	1500VAC, 50Hz, 1 min	电流消耗 Current consumption	≤33mA
耐振动性 Vibration resistance	30~55~30Hz, 振幅0.15mm Amplitude 0.15mm	声压电平 Sound pressure level	约85dB (1m) About 85dB (1m)
谐振频率 Resonant frequency	2.8kHz ± 300Hz	绝缘电阻 Insulation resistance	≥100M Ω (500VDC)
基座材料 Base material	PA(V0)	尾部配置 Tail configuration	接线柱 Terminal Blocks
光亮度 Brightness	≥20cd/m²	相比漏电起痕指数 Comparative tracking Index	CTI≥275
紧固扭矩 Tightening torque	螺母: 0.6N·m 螺丝: 0.5N·m Nut: 0.6N·m Screw: 0.5N·m	接线能力 Wiring capacity	1mm² (18AWG)以内 × 1 Within 1mm²(18AWG) × 1
间歇特性 Intermittent characteristics	42次/分钟(间断蜂鸣) 42 times/min(Intermittent beep)	防护等级 IP class	IP67

产品图样 Product images

规格参数 Specification

外形尺寸 Dimension



- 蜂鸣类型□
Beep Type

带灯颜色
LED Color

带灯电压▲
Voltage

防护等级※
IP Class

壳体材质
Material
- M:连续蜂鸣+常亮/JM:间断蜂鸣+闪亮
M: Steady Light+ Continuous Sound/JM: Flashing Light+Intermittent Sound

R

12V/24V (直流DC)

IP67

头部:不锈钢/外壳:PC/底座:PA
Head:Stainless steel/Body:PC/Base:PA

