


PANCON
CONNECTORS




Current Rating: 5.0 - 8.0 AMP
Voltage Rating: 300V AC
Contact Resistance: 10mΩ max.
Withstand Voltage: 2200V AC/Minute
Insulation Resistance: 5000MΩ min.
Operation Temperature: -55°C to +105°C

Contact Material: Copper Alloy
Contact Plating: Sn over Ni (Au on request)
Insulator Material: PA66 UL94 V-2

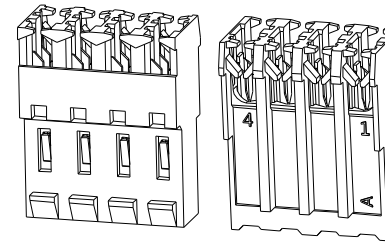

Plating
0,38μm Au over Ni: A
0,38μm selective Au over Ni: B
Tin: Blank

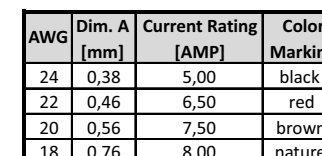

Pancon GmbH, Kaiser-Friedrich-Promenade 4, 61348 Bad Homburg v. d. H.
Tel: +49 6172 9180157, www.pancon.de