



UQS-COB-13W-WW-12V-5m-FC

Professional Led Strip, 13W/m




■ Features:

- Uniform lighting
- Uniform light line and high luminous intensity
- 3 years warranty



TECHNICAL DETAILS

MODEL	UQS-COB-13W-WW-12V-5m-FC	EPREL
Supply voltage	12V $\pm$ 0.5Vdc	
Power	13W/m	
Current	0,9 A/m	
Power per reel	65W	
Color temperature	3000K	
Beam angle	180°	
Luminous flux	1120 lm/m	
CRI	>90	
Maximum length for one sided supply	5m	
IP protection degree	IP20	
Working temperature	-20°C ÷ 50°C	
Storage temperature	-30°C ÷ 80°C	
LED QTY	528 LEDs/m	
Width PCB	8mm	
Cut section	Any length-free cut	
Connection wire	2 x AWG20 (0.52 mm ²) stranded wire, length = 360 mm: V+: red: V-:black.	
Dimensions (L x W x H)	5000 x 8 x 2.2 mm	
Packing	5m / reel (bag)	

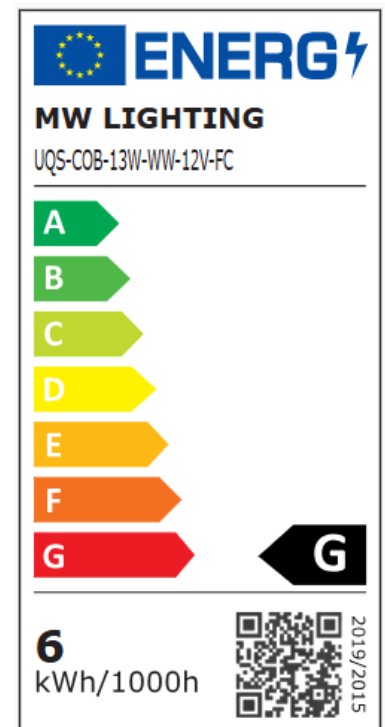

MECHANICAL SPECIFICATION:

