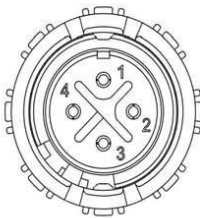
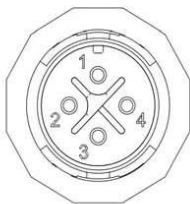
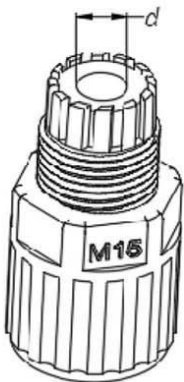
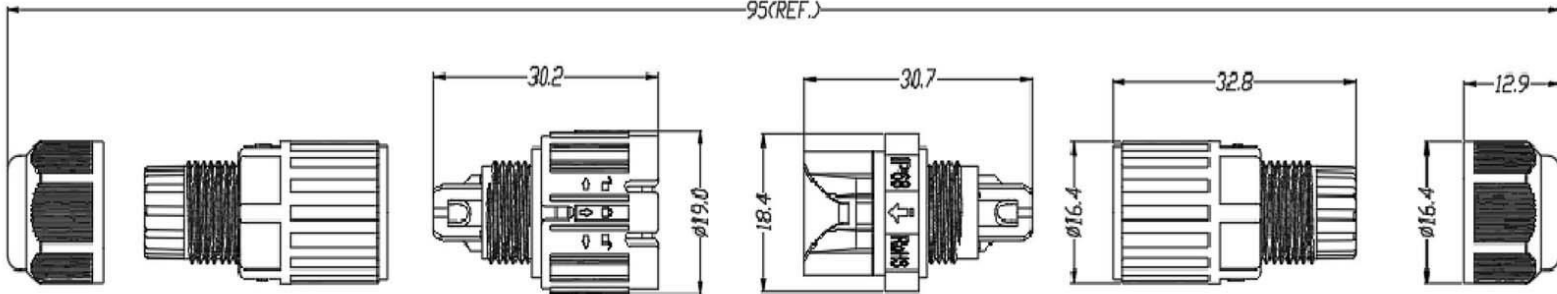


	1	2	3	4	5	6	7	8
A	Raw Material		PA66、SILICONE、 COPPER ALLOY		4 PIN  Female connector  Male connector 			
	Certification		CQC/RoHS/CE					
	Flame-resistant rating		UL94 V-0					
	Level of protection		IP68					
	Voltage rating/Current rating		450 V / 10 A					
	Withstanding voltage		2500 V					
	Cable gauge		0.5~1mm ²					
	Operating temperature		-40~105 ℃					
C								
	Type	Rubbers Diameter(d)	Outer Cable Diameter					
	A	φ 6.5 mm	φ 3.5~7 mm					
D	B	φ 4.5 mm	φ 2.5~4.5 mm					
E	Rubbers Diameter 							
F								
G								
H								
	1	2	3	4	5	6	7	8