




HQS-12W-60LED-NW-12V-50m

Professional Led Strip, 12 W/m

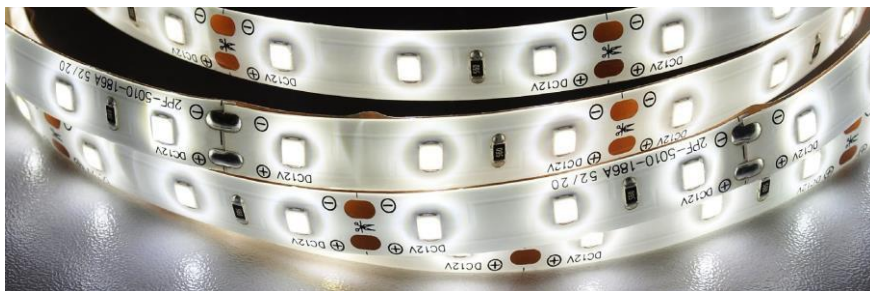

4000K
NEUTRAL WHITE

■ Features:

- Double copper layer
- Can be cut every segment 5 cm
- 3 years warranty




TECHNICAL DETAILS

MODEL	HQS-12W-60LED-NW-12V-50m	EPREL
Supply voltage	12V $\pm$ 0.5Vdc	
Power	12W/m	
Current	1 A/m	
Power per reel	60W	
Color temperature	4000K	
Beam angle	120°	
Luminous flux	1220 lm/m	
CRI	>80	
Maximum length for one sided supply	5m	
IP protection degree	IP33	
Working temperature	-25°C $\div$ 50°C	
Storage temperature	-25°C $\div$ 60°C	
LED QTY	60 LEDs/m	
Width PCB	10mm	
Cut section	50mm	
Connection wire	2 x AWG20 (0.52 mm ²) stranded wire, length = 140 mm: V+: red: V-:black.	
Dimensions (L x W x H)	50000 x 10 x 1.2 mm	
Packing	50m / reel (bag)	



MW LIGHTING

HQS-12W-60LED-NW-12V

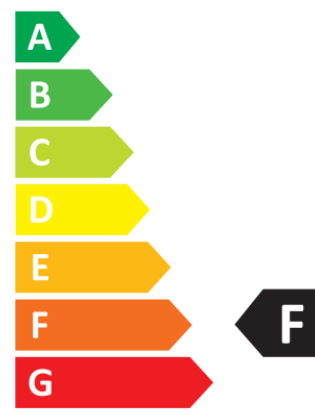

6
kWh/1000h



2019/2015

MECHANICAL SPECIFICATION:

