



HQS-9.6W-120LED-WW-24 V-50m

Professional Led Strip, 9.6 W/m



3000K
WARM WHITE

■ Features:

- Double copper layer
- Can be cut every segment 5 cm
- 3 years warranty




TECHNICAL DETAILS

MODEL	HQS-9.6W-120LED-WW-24V-50m	EPREL
Supply voltage	24V $\pm$ 0.5Vdc	
Power	9.6W/m	
Current	0.4 A/m	
Power per reel	48W	
Color temperature	3000K	
Beam angle	120°	
Luminous flux	980 lm/m	
CRI	>80	
Maximum length for one sided supply	5m	
IP protection degree	IP33	
Working temperature	-25°C $\div$ 50°C	
Storage temperature	-30°C $\div$ 60°C	
LED QTY	120 LEDs/m	
Width PCB	8mm	
Cut section	50mm	
Connection wire	2 x AWG20 (0.52 mm ²) stranded wire, length = 140 mm: V+: red: V-:black.	
Dimensions (L x W x H)	50000 x 8 x 1.2 mm	
Packing	50m / reel (bag)	



MW LIGHTING

HQS-9.6W-120LED-WW-24V

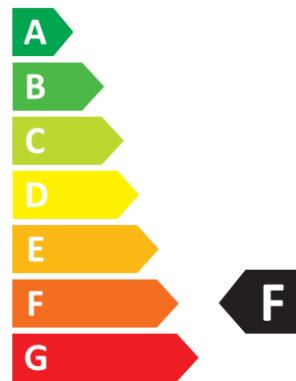

5
kWh/1000h



2019/2015

MECHANICAL SPECIFICATION:

