



HQS-9.6W-120LED-NW-12V

Professional Led Strip, 9.6 W/m



■ Features:

- Double copper layer
- Can be cut every segment 2.5 cm
- 3 years warranty

4000K
NEUTRAL WHITE

IP33

CRI>80

120°
lens

UK
CA

CE


3
year warranty

TECHNICAL DETAILS

MODEL	HQS-9.6W-120LED-NW-12V
Supply voltage	12V $\pm$ 0.5Vdc
Power	9.6W/m (48W/reel)
Current	0.8 A/m (4A/roll)
Power per reel	48W
Color temperature	4000K
Beam angle	120°
Luminous flux	1040 lm/m (5200lm/roll)
CRI	>80
Maximum length for one sided supply	5m
IP protection degree	IP33
Working temperature	-25°C ÷ 50°C
Storage temperature	-30°C ÷ 60°C
LED QTY	120 LEDs/m (600 LEDs/reel)
Width PCB	8mm
Cut section	25mm
Connection wire	2 x AWG20 (0.52 mm ²) stranded wire, length = 140 mm: V+: red: V-:black.
Dimensions (L x W x H)	5000 x 8 x 1.2 mm
Packing	5m / reel (bag)



MW LIGHTING
HQS-9.6W-120LED-NW-12V

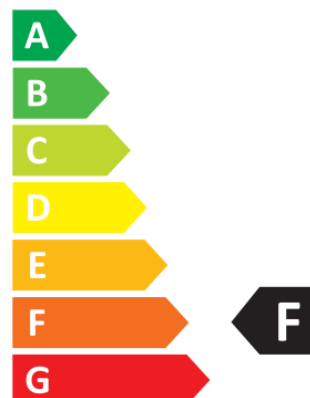

5
kWh/1000h



2019/2015

MECHANICAL SPECIFICATION:

