



HQS-6W-60LED-WW-24V

Professional Led Strip, 6 W/m



■ Features:

- Double copper layer
- Can be cut every segment 10 cm
- 3 years warranty




TECHNICAL DETAILS

MODEL	HQS-6W-60LED-WW-24V
Supply voltage	24V $\pm$ 0.5Vdc
Power	6W/m (30W/reel)
Current	0.25 A/m (1.25A/roll)
Power per reel	30W
Color temperature	3000K
Beam angle	120°
Luminous flux	620 lm/m (3010lm/roll)
CRI	>80
Maximum length for one sided supply	5m
IP protection degree	IP33
Working temperature	-25°C $\div$ 50°C
Storage temperature	-30°C $\div$ 60°C
LED QTY	60 LEDs/m (300 LEDs/reel)
Width PCB	8mm
Cut section	100mm
Connection wire	2 x AWG20 (0.52 mm ²) stranded wire, length = 140 mm: V+: red: V-:black.
Dimensions (L x W x H)	5000 x 8 x 1.2 mm
Packing	5m / reel (bag)



MW LIGHTING
HQS-6W-60LED-WW-24V

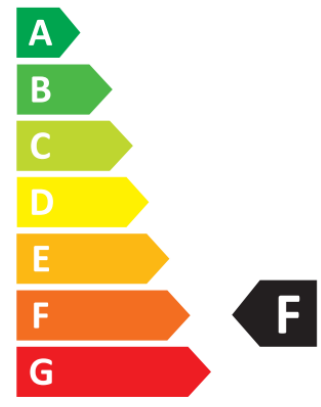

3
kWh/1000h



2019/2015

MECHANICAL SPECIFICATION:

