



HQS-12W-60LED-WW-24V

Professional Led Strip, 12 W/m



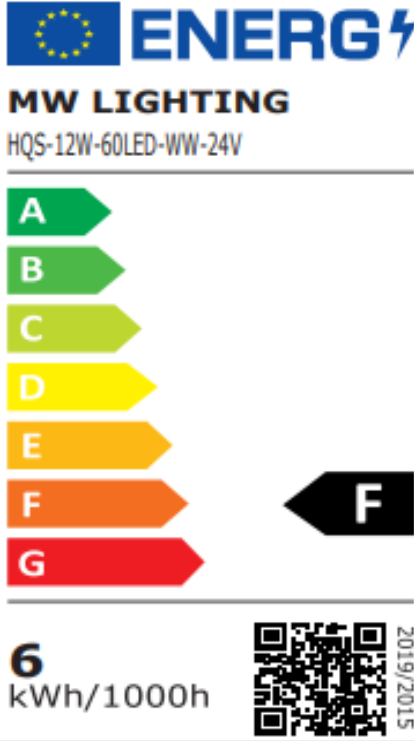
3000K
WARM WHITE

■ Features:

- Double copper layer
- Can be cut every segment 5 cm
- 3 years warranty



TECHNICAL DETAILS

MODEL	HQS-12W-60LED-WW-24V	EPREL
Supply voltage	24V $\pm$ 0.5Vdc	
Power	12W/m (30W/reel)	
Current	0,5 A/m (2,5A/roll)	
Power per reel	60W	
Color temperature	3000K	
Beam angle	120°	
Luminous flux	1180 lm/m (4720lm/roll)	
CRI	>80	
Maximum length for one sided supply	5m	
IP protection degree	IP33	
Working temperature	-25°C ÷ 50°C	
Storage temperature	-25°C ÷ 60°C	
LED QTY	60 LEDs/m (300 LEDs/reel)	
Width PCB	10mm	
Cut section	100mm	
Connection wire	2 x AWG20 (0.52 mm ²) stranded wire, length = 140 mm: V+: red: V-:black.	
Dimensions (L x W x H)	5000 x 10 x 1.2 mm	
Packing	5m / reel (bag)	

MECHANICAL SPECIFICATION:

