

Folding Handles

Steel / Stainless Steel,
in Both End Positions Retained

SPECIFICATION

Handle

- Steel **ST**
 - Chrome plated **CR**
- Stainless steel AISI 303 **NI**
 - Matte shot-blasted finish **GS**

Hex nuts ISO 8675

Stainless steel

Washers DIN 125


Stainless steel

INFORMATION

Folding handles GN 425.2 are used in places where the handle must not protrude or protrude only a short distance.
In both positions the handle is retained by a spring loaded detent.

TECHNICAL INFORMATION

- Load Rating Information (see page)
- Stainless Steel Characteristics (see page A26)

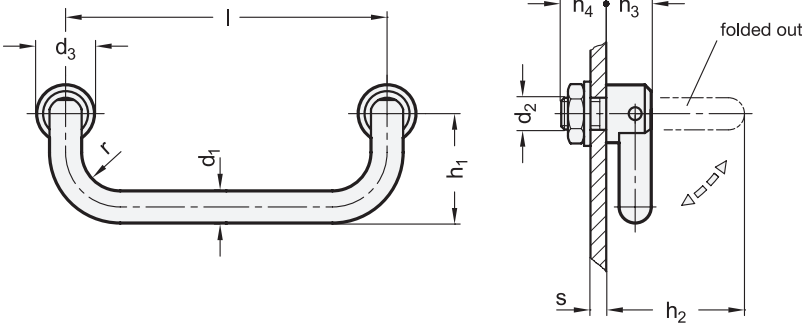

GN 425.2-ST

Description	d1	l ±0.25	d2	d3	h1	h2	h3	h4	r	s max.	⚖
GN 425.2-ST-10-100-CR	10	100	M 10 x 1	18	34	43	14	14	12	6	150
GN 425.2-ST-10-120-CR	10	120	M 10 x 1	18	34	43	14	14	12	6	163
GN 425.2-ST-10-180-CR	10	180	M 10 x 1	18	34	43	14	14	12	6	200

GN 425.2-NI

STAINLESS STEEL

Description	d1	l ±0.25	d2	d3	h1	h2	h3	h4	r	s max.	⚖
GN 425.2-NI-6-55-GS	6	55*	M 6	12	21	27.5	9.5	10	6	4	39
GN 425.2-NI-6-64-GS	6	64	M 6	12	21	27.5	9.5	10	6	4	41
GN 425.2-NI-6-88-GS	6	88*	M 6	12	21	27.5	9.5	10	6	4	47
GN 425.2-NI-10-100-GS	10	100	M 10 x 1	18	34	43	14	14	12	6	150
GN 425.2-NI-10-120-GS	10	120	M 10 x 1	18	34	43	14	14	12	6	163
GN 425.2-NI-10-180-GS	10	180	M 10 x 1	18	34	43	14	14	12	6	200

* Suitable for 19" rack and enclosure layout