


article#	U25050
article description	Charging socket USB type A double 2x5V(2,1A)
description long	USB charging socket 5V/2,1A (2x) with integrated power supply unit for charging and powering mobile devices with USB connector plastic housing, color: similar to RAL1023 2 pcs. USB type A sockets for simultaneous charging of 2 USB devices Integrated electronic short circuit and overload protection Input: 240V AC, 50/60Hz, 0,15A (ext. back-up fuse 6A characteristic B necessary) Power supply: 2x connecting wires AWG 22-18, length: approx. 180mm Output voltage: 2x 5V DC No-load consumption: 0.3W max. Rated current: per connector 2.1A - with integrated load management 2.1A max. Overvoltage category: II, protection class: II dimensions HxWxD: 62,5x50x50,3 mm, flange hole spacing: 38x38 mm incl. flange gasket (rubber) Protection class: IP54 / IP20 (closed / open lid)
GTIN (EAN)	9003399516733
country of origin	CN
customs number	85366990
net weight	0.070 kg
packaging quantity	20
minimum order quantity	20

ETIM 9.0	EC001264
Duct installation	True
Type of fastening	Screwing
Assembly arrangement	Other
Type of connector	USB
Suitable for number of connectors	2
Colour	Yellow
RAL-number	1023
Connection type	Other
Outlet direction	Straight
Degree of protection (IP)	IP54
Width of device	50 mm
Height of device	62.5 mm
Depth of device	50.3 mm

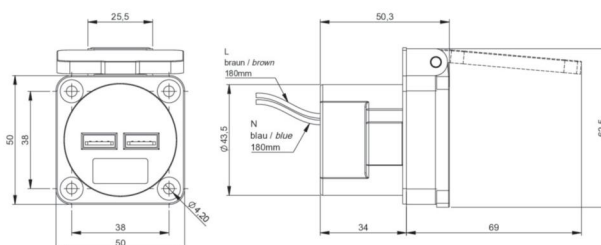

<https://www.pcelectric.at/shop/en/?func=detail&artnr=U25050>