



乐清市裕林电子有限公司

Yueqing Yulin Electronic Co., Ltd

Add:F/6 No.19 KeAiSi Road XiangYang Industrial Zone,Liushi Town,YueQing,Zhejiang China 325600

Tel: 0577-27878383

Fax: 0577-27878383

Website: www.filn.com

SPECIFICATION FOR APPROVAL

规格说明书

CUSTOMER'S CODE

本厂代码:

DESCRIPTION

品 名: Push Button Switch

SPECIFICATION

规 格: 12mm

DATE

编制日期:

PART NO.

本厂型号: FLM12-FW-1-XX000

REFERENCE No.

档案编号:

Form Designer 编 制	Qualified By 审 核	Approved By 批 准
吴维继	陈永强	陈 平



乐清市裕林电子有限公司

Yueqing Yulin Electronic Co., Ltd

Add: F/6 No.19 KeAiSi Road XiangYang Industrial Zone, Liushi Town, YueQing, Zhejiang China 325600

Tel: 0577-27878383


Fax: 0577-27878383

Website: www.filn.com


1. 图片 Picture:




2. 图纸 Drawing

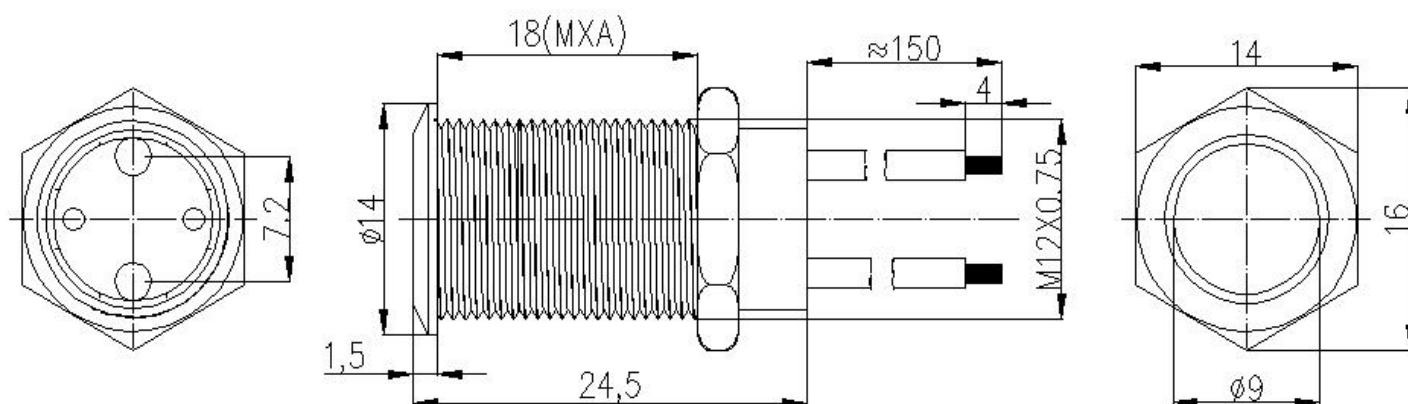

电气简图

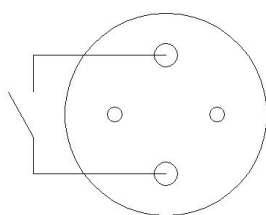

安装孔图

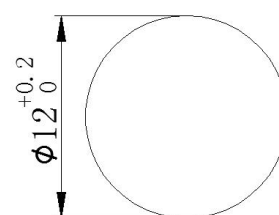



乐清市裕林电子有限公司

Yueqing Yulin Electronic Co., Ltd

Add:F/6 No.19 KeAiSi Road XiangYang Industrial Zone,Liushi Town,YueQing,Zhejiang China 325600

Tel: 0577-27878383

Fax: 0577-27878383

Website: www.filn.com

3 配件材料 Component Material

配件名 Component name	材料 Material
导光按键 Lens	/
按键 Actuator	304 不锈钢/6063 铝合金 304 Stainless Steel/6063 Aluminum Alloy
外壳套筒 Housing	H59黄铜/304 不锈钢/6063 铝合金 H59 Brass/304 Stainless Steel/6063 Aluminum Alloy
按钮引脚 Connect Terminal	H62 铜合金 H62 Brass
防水圈 O-Ring	SIL 硅胶 SIL silica gel
螺帽 Nut	H59 黄铜 H59 Brass
底座 Base	PA66+GF20%阻燃尼龙 PA66+GF20% nylon
光源 Light source	/
电阻 Resistor	/
触点 Contacts	银触点 AgCdO12

4 性能参数 Performance Parameter

项目 Items	参数 Parameter
开关额定电压 Switch Rated Voltage	36V DC 250V AC
开关额定电流 Switch Rated Current	2A DC 1A AC
指示灯额定电压 Led Rated Voltage	/
指示灯额定电流 Led Rated Current	/
额定功率 Rated Power	72W(DC) 250W(AC)
绝缘耐压 Insulation and voltage resistance	1500V
接触电阻: Contact Resistance:	$\leq 50m\Omega$ $\leq 50m\Omega$
绝缘电阻: Isolation Resistance:	$\geq 1000M\Omega$ $\geq 1000M\Omega$
机械寿命 Mechanical Life	50 万次 500,000times
电气寿命 Electrical Life	10 万次 100,000times
工作环境温度 Operating Temperature	-25℃~+85℃
防护等级(头部) IP Degree	IP65 IK08
指示灯颜色 Led Color	/