



乐清市裕林电子有限公司

Yueqing Yulin Electronic Co., Ltd

Add: F/6 No.19 KeAiSi Road XiangYang Industrial Zone, Liushi Town, YueQing, Zhejiang China 325600

Tel: 0577-27878383

Fax: 0577-27878383

Website: www.filn.com

SPECIFICATION FOR APPROVAL

规格说明书

CUSTOMER'S CODE

本厂代码:

DESCRIPTION

品 名:

Push Button Switch

SPECIFICATION

规 格:

19mm

DATE

编制日期:

PART NO.

本厂型号:

FLM19-FJ-4-XX000

REFERENCE No.

档案编号:

Form Designer 编 制	Qualified By 审 核	Approved By 批 准
吴维继	陈永强	陈 平



乐清市裕林电子有限公司

Yueqing Yulin Electronic Co., Ltd

Add: F/6 No.19 KeAiSi Road XiangYang Industrial Zone, Liushi Town, YueQing, Zhejiang China 325600

Tel: 0577-27878383


Fax: 0577-27878383

Website: www.filn.com

1. 图片 Picture:





2. 图纸 Drawing

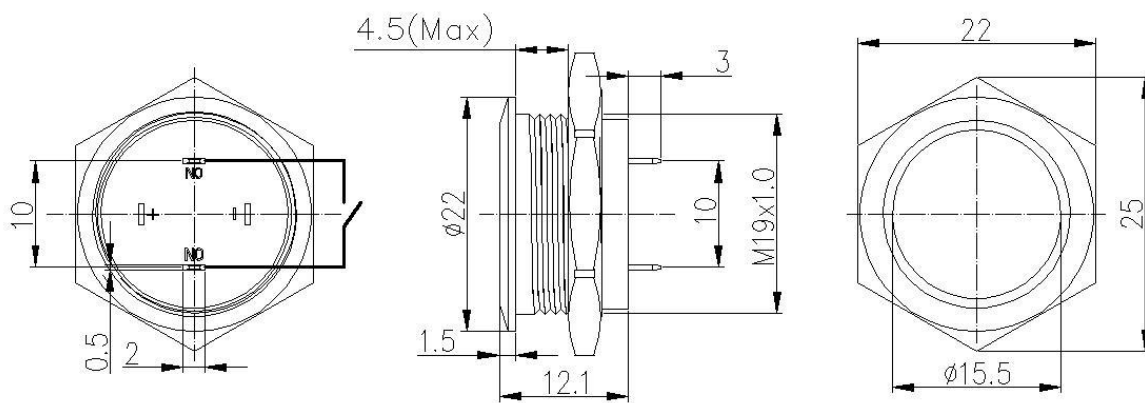

电气简图

安装孔图

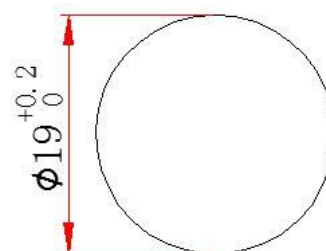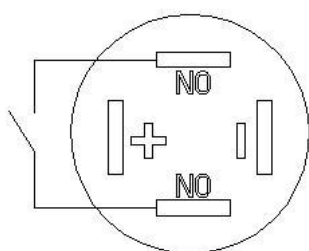



乐清市裕林电子有限公司

Yueqing Yulin Electronic Co., Ltd

Add: F/6 No.19 KeAiSi Road XiangYang Industrial Zone, Liushi Town, YueQing, Zhejiang China 325600

Tel: 0577-27878383

Fax: 0577-27878383

Website: www.filn.com

3 配件材料 Component Material

配件 Component name	材料 Material
导光按键 Lighting Source	/
按键 Actuator	304 不锈钢/6063 铝合金 304 Stainless Steel/6063 Aluminum Alloy
外壳套筒 Housing	H59 黄铜/304 不锈钢 /6063 铝合金 H59 Brass/304 Stainless Steel/6063 Aluminum Alloy
按钮引脚 Connect Terminal	H62 铜合金 H62 Copper Alloy
防水圈 O-Ring	SIL 硅胶 SIL silica gel
螺帽 Nut	H59 黄铜 H59 Brass
底座 Base	PA66+GF20%阻燃尼龙 PA66+GF20% nylon
光源 Light source	/
电阻 Resistor	/
触点 Contacts	银触点 AgCdO12

4 性能参数 Performance Parameter

项目 Items	参数 Parameter
开关额定电压 Switch Rated Voltage	12V DC
开关额定电流 Switch Rated Current	50mA DC
指示灯额定电压 Led Rated Voltage	/
指示灯额定电流 Led Rated Current	/
额定功率 Rated Power	0.6W (DC)
绝缘耐压 Insulation and voltage resistance	250V
接触电阻: Contact Resistance:	≤50mΩ
绝缘电阻: Isolation Resistance:	≥1000MΩ
机械寿命 Mechanical Life	10 万次 100,000times
电气寿命 Electrical Life	50,000times (12V/5mA)
工作环境温度 Operating Temperature	-25℃~+85℃
防护等级(头部) IP Degree	IP67 IK09
指示灯颜色 Led Color	/