



乐清市裕林电子有限公司

Yueqing Yulin Electronic Co., Ltd

Add:F/6 No.19 KeAiSi Road XiangYang Industrial Zone,Liushi Town,YueQing,Zhejiang China 325600

Tel: 0577-27878383

Fax: 0577-27878383

Website: www.filn.com

SPECIFICATION FOR APPROVAL

规格说明书

CUSTOMER'S CODE

本厂代码:

DESCRIPTION

品 名:

Push Button Switch

SPECIFICATION

规 格:

19mm

DATE

编制日期:

PART NO.

本厂型号:

FLM19-FW-1-XX000

REFERENCE No.

档案编号:

Form Designer 编 制	Qualified By 审 核	Approved By 批 准
吴维继	陈永强	陈 平



乐清市裕林电子有限公司

Yueqing Yulin Electronic Co., Ltd

Add: F/6 No.19 KeAiSi Road XiangYang Industrial Zone, Liushi Town, YueQing, Zhejiang China 325600

Tel: 0577-27878383


Fax: 0577-27878383

Website: www.filn.com

1. 图片 Picture





2. 图纸 Drawing

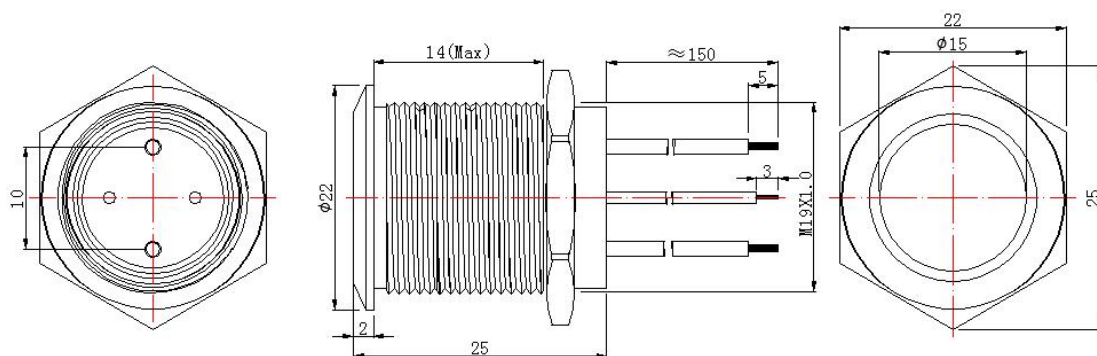

电气简图

安装孔图

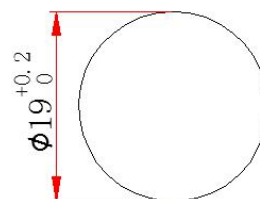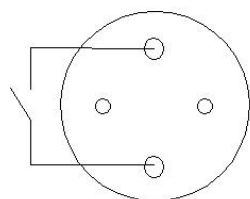



乐清市裕林电子有限公司

Yueqing Yulin Electronic Co., Ltd

Add:F/6 No.19 KeAiSi Road XiangYang Industrial Zone,Liushi Town,YueQing,Zhejiang China 325600

Tel: 0577-27878383

Fax: 0577-27878383

Website: www.filn.com

3 配件材料 Component Material

配件名 Component name	材料 Material
导光按键 Lens	/
按键 Actuator	304 不锈钢/6063 铝合金 304 Stainless Steel/6063 Aluminum Alloy
外壳套筒 Housing	H304不锈钢/6063铝合金 304 Stainless Steel/6063 Aluminum Alloy
按钮导线 Wire Leading	0.5-0.75mm ² PTFE 铁氟龙 高温导线 0.5-0.75mm ² PTFE Teflon Wire
防水圈 O-Ring	SIL 硅胶 SIL silica gel
螺帽 Nut	H59 黄铜 H59 Brass
底座 Base	PA66+GF20%阻燃尼龙 PA66+GF20% nylon
光源 Light source	/
电阻 Resistor	/
触点 Contacts	银触点 AgCdO12

4 性能参数 Performance Parameter

项目 Items	参数 Parameter
开关额定电压 Switch Rated Voltage	36V DC 250V AC
开关额定电流 Switch Rated Current	5A DC 5A AC
指示灯额定电压 Led Rated Voltage	/
指示灯额定电流 Led Rated Current	/
额定功率 Rated Power	180W(DC) 1250W(AC)
绝缘耐压 Insulation and voltage resistance	1800V
接触电阻 Contact Resistance	≤50mΩ
绝缘电阻 Isolation Resistance	≥100MΩ
机械寿命 Mechanical Life	50 万次 500,000times
电气寿命 Electrical Life	100,000times (250V/3A) 50,000times (250V/5A)
工作环境温度 Operating Temperature	-25°C~+85°C
防护等级(头部) IP Degree	IP65 IK08
指示灯颜色 Led Color	/