


WM-80ST-03

TV wall mount (full-motion), 37" - 80"

- Position your screen perfectly
- Lightweight and maneuverable design

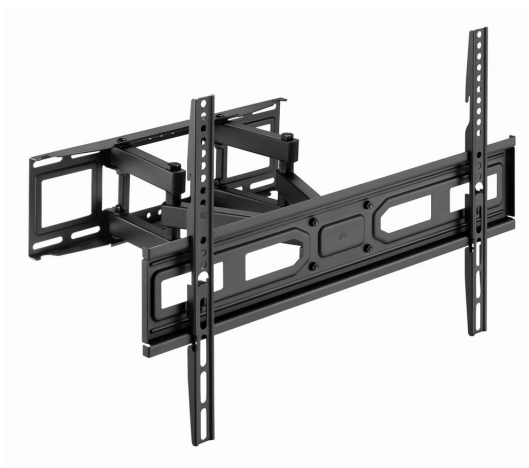

Features

- Double-arm full-motion TV wall mount
- Supports most 37" 80" LCD TV's
- VESA compatible, max. 600 mm x 400 mm
- Allows up to 120 degrees swivel and 18 degrees tilting
- Distance to wall: 67 355 mm
- Includes all necessary installation materials

Packaging

Q'ty in crtn, pcs	4
Crtn volume, CUM	0.044649
Crtn weight, kgs	16.27
Individual package size LxWxH:	645x155x62 mm
Carton size LxWxH:	660x330x205 mm
Country of origin	CN
Barcode	8716309127783
Customs code	8302500000

Package contents

Wall mount elements
Installation accessories kit
Installation manual

Certificates



Specifications

Material: steel, plastic

Surface finish: powder coating

Color: black

Fit screen size: 37" 80"

VESA compatible: 100 x 100, 100 x 150, 100 x 200, 150 x 100, 150 x 150, 200 x 100, 200 x 200, 300 x 200, 300 x 300, 400 x 200, 400 x 300, 400 x 400, 600 x 200, 600 x 300, 600 x 400 mm

Weight capacity: 40 kg

Profile: 67 ~ 355 mm

Tilt range: +3 ° ~ -15 °

Swivel range: +60 ° ~ -60 °

Screen level: +3 ° ~ -3 °

Installation: solid wall, double stud (406 mm)

Cable management: yes

Net weight: 3.6 kg

Dimensions: 355 x 640 x 420 mm