



Mi 9301



- Empty box
- dimensions H x W x D: 450 x 315 x 170 mm
- with hinged lid, hinge, external

ELECTRICAL PROPERTIES

Rated insulation voltage:

Rated insulation voltage	Voltage type
$U_i = 690\text{ V}$	a.c.
$U_i = 1000\text{ V}$	d.c.

Protection class: II

CONNECTION DATA

MECHANICAL PROPERTIES

Protection cover according to DIN EN 61439 via lid

Type of lid fastening:	Tool operation
Can be combined:	Yes
IP degree of protection:	IP65
Impact strength:	IK08

AMBIENT CONDITIONS

Application area:	Indoor installation
Maximum ambient temperature 24 h:	35 °C
Ambient temperature:	-25 °C up to +70 °C

MATERIAL PROPERTIES

Material:	Polycarbonate Under the influence of acid (10%), the hinges may become discoloured and brittle. The functionality is not limited.
Glow wire test according to IEC 60695-2-11:	960 °C
UV-beständig nach DIN EN 61439-1:	Yes
Halogen-free:	Yes
Silicone-free:	Yes

DIMENSIONS

Height:	450 mm
Width:	315 mm
Depth:	170 mm
Net weight:	2.806 kg
Mounting height:	425 mm
Mounting width:	275 mm
Mounting depth:	

Equipping	Depth
without	150 mm
Mounting plate	146 mm
DIN rail	135 mm

COLOURS

Colour of the lid: Grey
Bottom part colour: Grey

CERTIFICATES

conforming to the standards: IEC 61439-2

SALES DATA


Product number: 20001050
EAN: 4012591111054
Pack unit: 1
Customs tariff number: 85371098
ETIM class: DYNAMIC: EC000058 - Empty cabinet
ETIM-9.0: EC000058 - Empty cabinet
ETIM-8.0: EC000058 - Empty cabinet
ETIM-7.0: EC000058 - Empty cabinet
ETIM-6.0: EC000058 - Empty cabinet
ETIM-5.0: EC000058 - Empty cabinet
ETIM-4.0: EC000058 - Empty cabinet

NOTE


Note on the product:

- trilaterally combinable
- lid hinges attached

DRAWINGS

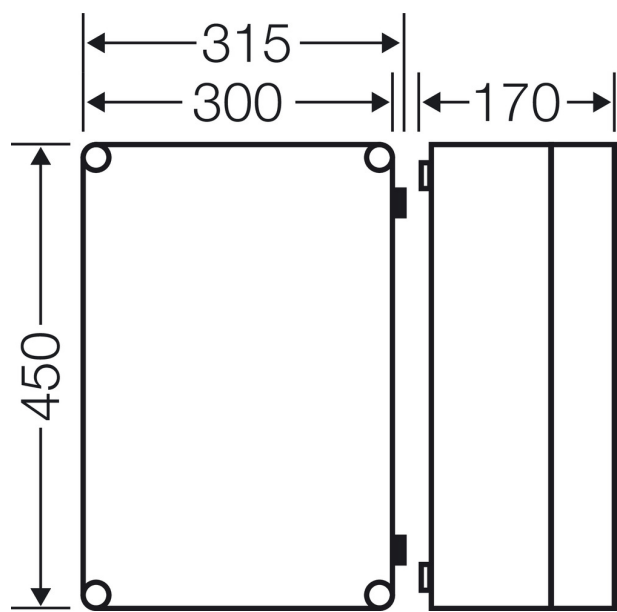

2xM20, 10xM25

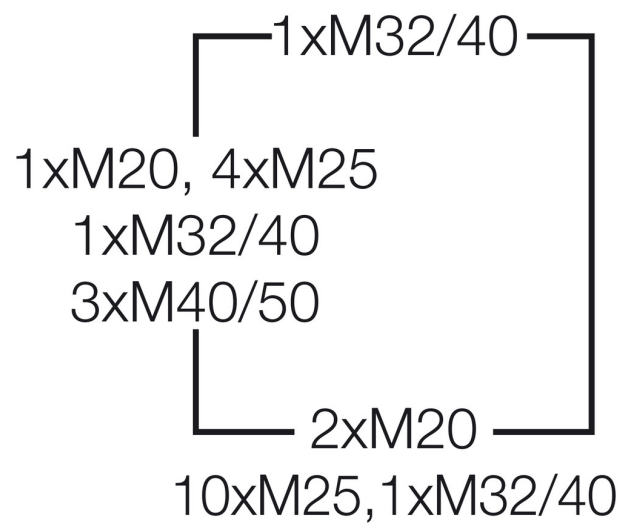

1xM32/40

1xM20, 4xM25

1xM32/40

3xM40/50

2xM20

10xM25, 1xM32/40