



Mi 9311



- Empty box
- dimensions H x W x D: 450 x 315 x 214 mm
- with hinged lid, hinge, external

ELECTRICAL PROPERTIES

Rated insulation voltage:

Rated insulation voltage	Voltage type
U _i = 690 V	a.c.
U _i = 1000 V	d.c.

Protection class: II

CONNECTION DATA

MECHANICAL PROPERTIES

Protection cover according to DIN EN 61439 via lid	
Type of lid fastening:	Tool operation
Can be combined:	Yes
IP degree of protection:	IP65
Impact strength:	IK08

AMBIENT CONDITIONS

Application area:	Indoor installation
Maximum ambient temperature 24 h:	35 °C
Ambient temperature:	-25 °C up to +70 °C

MATERIAL PROPERTIES

Material:	Polycarbonate Under the influence of acid (10%), the hinges may become discoloured and brittle. The functionality is not limited.
Glow wire test according to IEC 60695-2-11:	960 °C
UV-beständig nach DIN EN 61439-1:	Yes
Halogen-free:	Yes
Silicone-free:	Yes

DIMENSIONS

Height:	450 mm
Width:	315 mm
Depth:	214 mm
Net weight:	3.175 kg
Mounting height:	425 mm
Mounting width:	275 mm
Mounting depth:	

Equipping	Depth
without	195 mm
Mounting plate	191 mm
DIN rail	180 mm

COLOURS

Colour of the lid:	Grey
Bottom part colour:	Grey

CERTIFICATES

conforming to the standards:	IEC 61439-2
------------------------------	-------------

SALES DATA


Product number:	20001052
EAN:	4012591111078
Pack unit:	1
Customs tariff number:	85371098
ETIM class:	DYNAMIC: EC000058 - Empty cabinet ETIM-9.0: EC000058 - Empty cabinet ETIM-8.0: EC000058 - Empty cabinet ETIM-7.0: EC000058 - Empty cabinet ETIM-6.0: EC000058 - Empty cabinet ETIM-5.0: EC000058 - Empty cabinet ETIM-4.0: EC000058 - Empty cabinet


NOTE

Note on the product:

- trilaterally combinable
- lid hinges attached

DRAWINGS

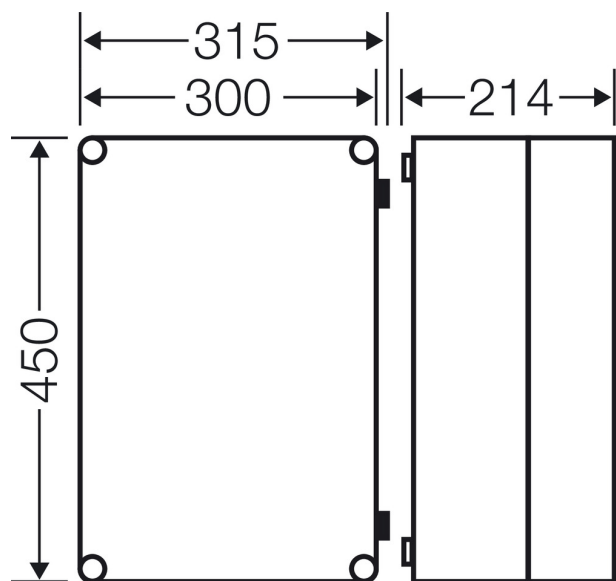

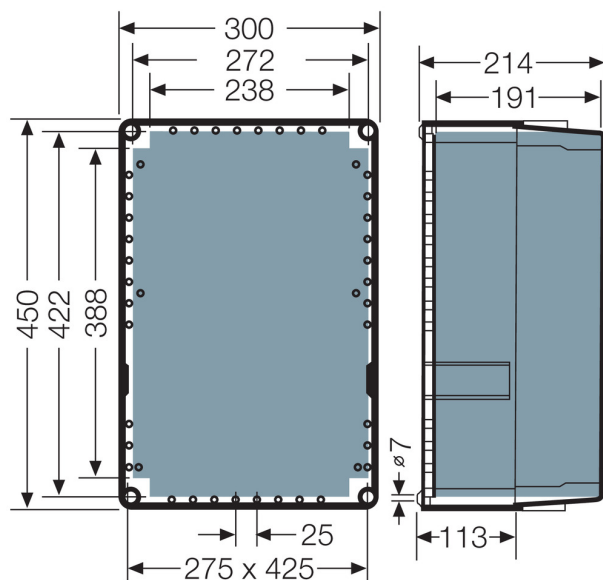

2xM20, 10xM25

1xM32/40

1xM20, 4xM25

1xM32/40

3xM40/50

2xM20

10xM25, 1xM32/40