




## Mi KL 6

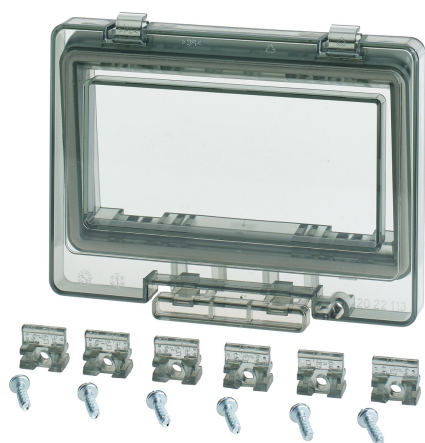

- Hinged flap

### CONNECTION DATA

### MECHANICAL PROPERTIES

Delivered accessories:

IP degree of protection:

Sealable without accessories:

With hinged flap:

Fastening material, drilling and sawing template

IP65

Yes

Lid sealable without further accessories

Yes

### AMBIENT CONDITIONS

Application area:

Maximum ambient temperature 24 h:

Ambient temperature:

Relative humidity:

Indoor installation

35 °C

-5 °C up to +40 °C

≤ 50 % at 40 °C, ≤ 100 % at 25 °C

### DIMENSIONS

Height:

Width:

Depth:

Net weight:

112 mm

141 mm

20 mm

0.12 kg

## CERTIFICATES

conforming to the standards:

IEC 61439-2

## SALES DATA

|                        |                                                                                                                                                                                                                                                            |
|------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Product number:        | 2000060                                                                                                                                                                                                                                                    |
| EAN:                   | 4012591650607                                                                                                                                                                                                                                              |
| Pack unit:             | 1                                                                                                                                                                                                                                                          |
| Customs tariff number: | 85371098                                                                                                                                                                                                                                                   |
| ETIM class:            | DYNAMIC: EC002527 - Window (enclosure/cabinet)<br>ETIM-4.0: EC002527 - Window (enclosure/cabinet)<br>ETIM-5.0: EC002527 - Window (enclosure/cabinet)<br>ETIM-6.0: EC002527 - Window (enclosure/cabinet)<br>ETIM-7.0: EC002527 - Window (enclosure/cabinet) |

## NOTE

Note on the product:

- Hinged flap lockable with accessories

## DRAWINGS

