


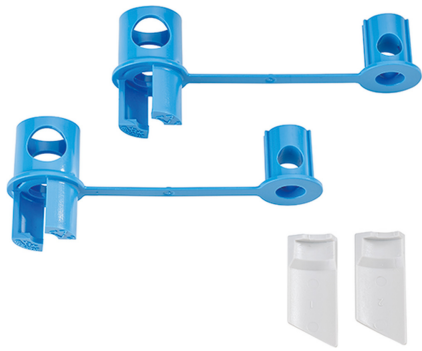

Mi SV 2

- Locking device insertion conversion kit
- set with 2 pieces
- for padlock

CONNECTION DATA

MECHANICAL PROPERTIES

Type of lid fastening:	For padlock
Maximum bracket diameter:	10 mm

AMBIENT CONDITIONS

Application area:	Indoor installation
Maximum ambient temperature 24 h:	35 °C
Ambient temperature:	-5 °C up to +40 °C
Relative humidity:	≤ 50 % at 40 °C, ≤ 100 % at 25 °C

DIMENSIONS

Net weight:	0.016 kg
-------------	----------

CERTIFICATES

conforming to the standards:	IEC 61439-2
------------------------------	-------------

SALES DATA

Product number:	20001414
EAN:	4012591129417
Pack unit:	1
Customs tariff number:	85371098
ETIM class:	DYNAMIC: EC002620 - Components for installation (enclosure/ cabinet)
	ETIM-4.0: EC002620 - Components for installation (enclosure/ cabinet)
	ETIM-5.0: EC002620 - Components for installation (enclosure/ cabinet)
	ETIM-6.0: EC002620 - Components for installation (enclosure/ cabinet)
	ETIM-7.0: EC002620 - Components for installation (enclosure/ cabinet)

NOTE

Note on the product:

- Conversion kit for padlock