


TYPE 2060

Ø4MM STRAIGHT SAFETY BANANA JACKS
FICHES BANANES FEMELLES Ø4MM DE SÉCURITÉ DROITES
Ø4MM SICHERHEITS-KUPPLUNG

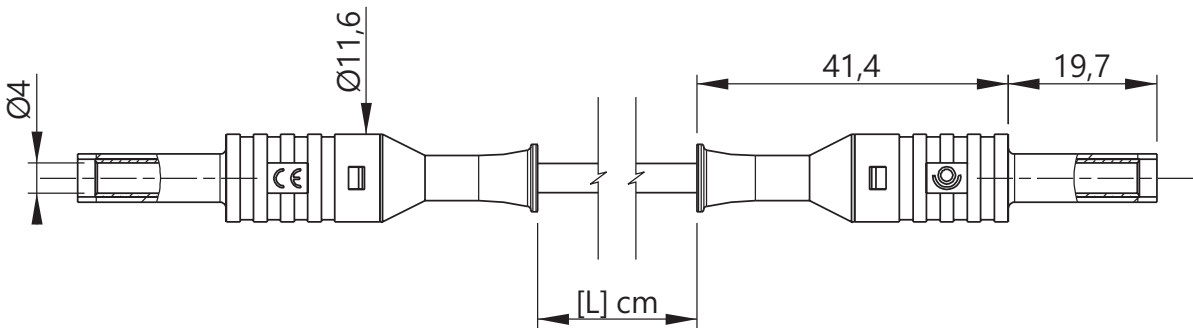

Reference
Référence
Bestell-Nr

206[X]-IEC-[L]-#

Wire
Câble
Litze

PVC [X] : 0,75mm² [0] • 1mm² [2] • 1,5mm² [5] • 2,5mm² [7]
SIL [X] : 0,75mm² [1] • 1mm² [9] • 1,5mm² [3] • 2,5mm² [4]

Lengths Longueurs Längen [cm]	Rated voltage Tension assignée Bemessungsspannung	Rated current Intensité assignée Bemessungsstrom	Contact parts Contacts Kontaktteile	Insulation Isolant Isolierteile	Colours [#] Couleurs [#] Farben [#]												
10 25 50 100 150 200	1000 V CAT III	0,75mm ² / 12A 1,00mm ² / 20A 1,50mm ² / 25A 2,50mm ² / 36A	Brass and CuBe / Ni coated (AuNi on request) Laiton et CuBe / Revêtement Ni (AuNi sur demande) CuBe und Messing vernickelt (AuNi auf Anfrage)	PP	<table><tr><td>R</td><td>N</td><td>BL</td></tr><tr><td> 2 </td><td> 0 </td><td> 6 </td></tr><tr><td>V</td><td>J</td><td>BC</td></tr><tr><td> 5 </td><td> 4 </td><td> 9 </td></tr></table>	R	N	BL	2	0	6	V	J	BC	5	4	9
R	N	BL															
2	0	6															
V	J	BC															
5	4	9															