

TYPE 209


Ø2MM SOCKET / SOLDER TERMINAL

FICHE FEMELLE Ø2MM / RACCORD SOUDURE

Ø2MM BUCHSE / LÖTANSCHLUSS

Reference
Référence
Bestell-Nr

209-#

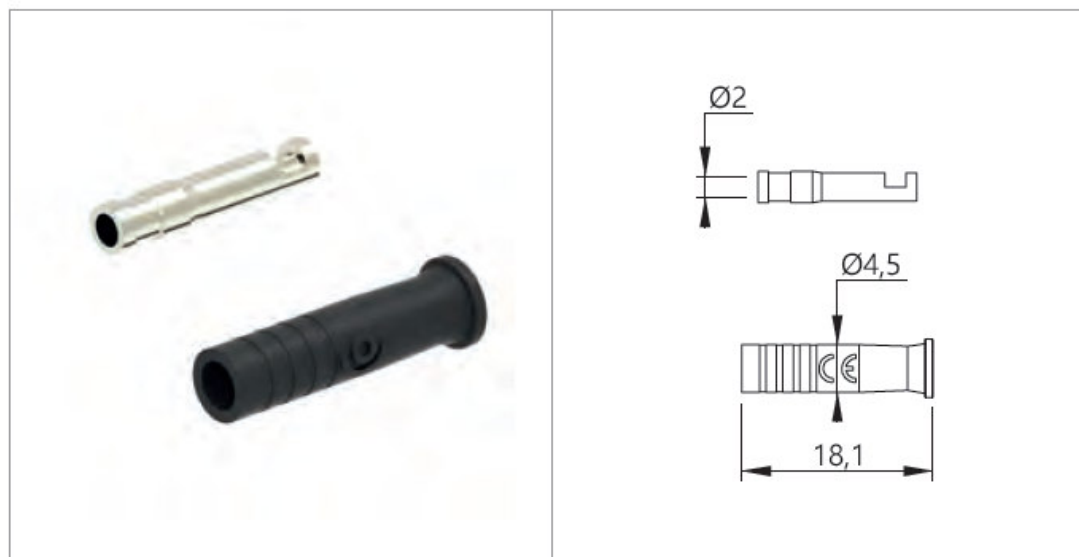

Rated voltage Tension assignée Bemessungsspannung	Rated current Intensité assignée Bemessungsstrom	Contact parts Contacts Kontaktteile	Insulation Isolant Isolierteile	Colours [#] Couleurs [#] Farben [#]
≤30VAC ≤60VDC	10A	Ni coated brass Laiton nickelé Messing vernickelt	PP	R N BL V J BC 2 0 6 5 4 9

With solder terminal for cables up to 0,50 mm²

Avec raccord à souder pour câbles jusqu'à 0,50 mm²

Lötanschluss bis 0,50 mm² Leitungsquerschnitt