


TYPE 227-12

Ø2MM STACKABLE SHUNT
SHUNT Ø2MM EMPILABLE
 Ø2MM STAPELBARER KURZSCHLUSSSTECKER

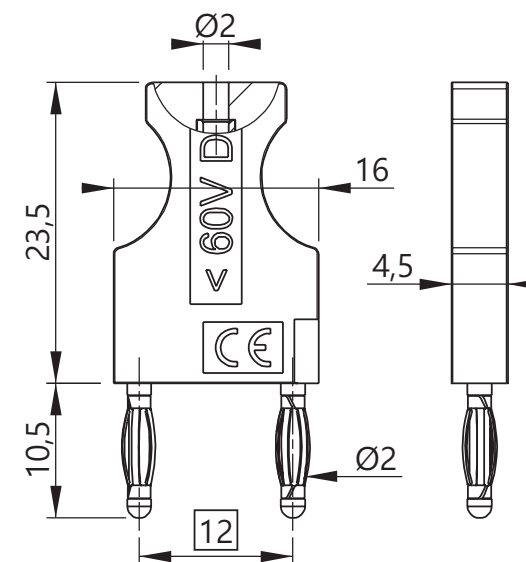

Reference
Référence 227-12-#
 Bestell-Nr

Rated voltage Tension assignée <i>Bemessungsspannung</i>	Rated current Intensité assignée <i>Bemessungsstrom</i>	Contact parts Contacts <i>Kontaktteile</i>	Insulation Isolant <i>Isolierteile</i>	Colours [#] Couleurs [#] <i>Farben [#]</i>
≤30VAC ≤60VDC	10A	Ni coated brass Laiton nickelé <i>Messing vernickelt</i>	PP	R N BL V J 2 0 6 5 4