


# TYPE 228-4

Ø2MM SAFETY BANANA SOCKET WITH Ø10MM ROUND NUT / M3  
THREADED STUD AND HEX NUTS TERMINAL  
**DOUILLE DE SÉCURITÉ Ø2MM AVEC ÉCROU ROND Ø10MM /**  
**RACCORD FILETAGE M3 AVEC ÉCROUS**  
**Ø2MM SICHERHEITS-EINBAUBUCHSE MIT Ø10MM RUNDMUTTER /**  
**M3 GEWINDEBOLZEN MIT MUTTERN**

**Version -C :** Ø10mm Screwed nut • **Ecrou Ø10mm vissé • Ø10mm Mutter geschraubt**

**Version -I :** Ø10mm Unscrewed nut • **Ecrou Ø10mm non vissé • Ø10mm Mutter nicht geschraubt**

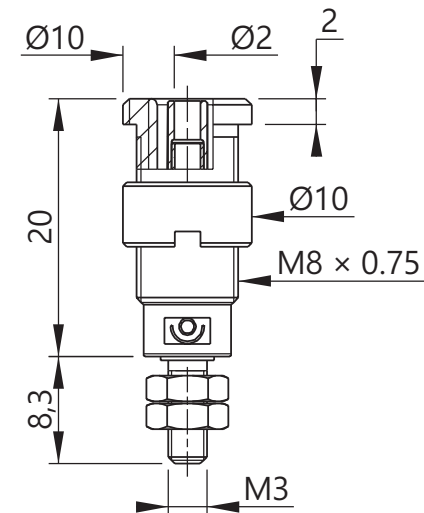

| Reference<br>Référence<br>Bestell-Nr | Rated voltage<br>Tension assignée<br>Bemessungsspannung | Rated current<br>Intensité assignée<br>Bemessungsstrom | Contact parts<br>Contacts<br>Kontaktteile                                                                                               | Insulation<br>Isolant<br>Isolierteile | Colours [#]<br>Couleurs [#]<br>Farben [#] |
|--------------------------------------|---------------------------------------------------------|--------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------|---------------------------------------|-------------------------------------------|
| 228-4-C-#                            | 600 V CAT II                                            | 10A                                                    | Brass / Ni coated (AuNi on request)<br><b>Laiton / Revêtement Ni (AuNi sur demande)</b><br><b>Messing vernickelt (AuNi auf Anfrage)</b> | PA6.6                                 | <div>R N BL</div> <div>2 0 6</div>        |
| 228-4-I-#                            | 600 V CAT II                                            | 10A                                                    | Brass / Ni coated (AuNi on request)<br><b>Laiton / Revêtement Ni (AuNi sur demande)</b><br><b>Messing vernickelt (AuNi auf Anfrage)</b> | PA6.6                                 | <div>V J BC</div> <div>5 4 9</div>        |