

TYPE 3240


Ø4MM INSULATED SOCKET / Ø4MM HOLE TERMINAL /
M6 THREADED STUD AND HEX NUT
**DOUILLE ISOLÉE Ø4MM / RACCORD TROU Ø4MM / FILETAGE
M6 AVEC ÉCROU**
Ø4MM ISOLIERTE BUCHSE / Ø4MM ANSCHLUSS /
M6 GEWINDEBOLZEN MIT MUTTER

Version -C : Screwed nut • **Ecrou vissé • Mutter geschraubt**

Version -I : Unscrewed nut • **Ecrou non vissé • Mutter nicht geschraubt**



Drilling • Perçage • Bohrung : $\text{Ø}8^{+0,1}_0$

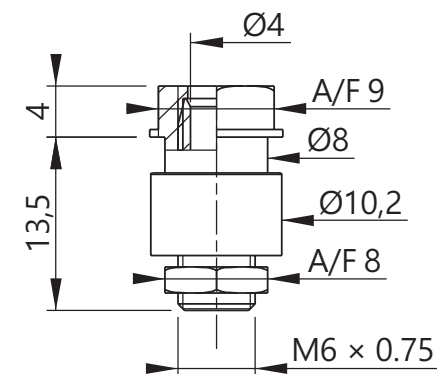

Reference Référence Bestell-Nr	Rated voltage Tension assignée Bemessungsspannung	Rated current Intensité assignée Bemessungsstrom	Contact parts Contacts Kontaktteile	Insulation Isolant Isolierteile	Colours [#] Couleurs [#] Farben [#]
3240-C-#	≤30VAC ≤60VDC	36A	Brass / Ni coated (AuNi on request) Laiton / Revêtement Ni (AuNi sur demande) Messing vernickelt (AuNi auf Anfrage)	POM	R 2 N 0 BL 6
3240-I-#	≤30VAC ≤60VDC	36A	Brass / Ni coated (AuNi on request) Laiton / Revêtement Ni (AuNi sur demande) Messing vernickelt (AuNi auf Anfrage)	POM	V 5 J 4 BC 9