


TYPE 3286

Ø4MM SAFETY BANANA SOCKET / 6,3 X 10 MM FLAT CONNECTING
TAB / PRESS FIT FIXING

**DOUILLE DE SÉCURITÉ Ø4MM / RACCORD PLAT 6,3 X 10 MM /
FIXATION PAR PRESSION**

Ø4MM SICHERHEITS-EINBAUBUCHSE / 6,3 X 10 MM
FLACHSTECKER / BEFESTIGUNG DURCH EINPRESSEN

Reference
Référence
Bestell-Nr **3286-#**

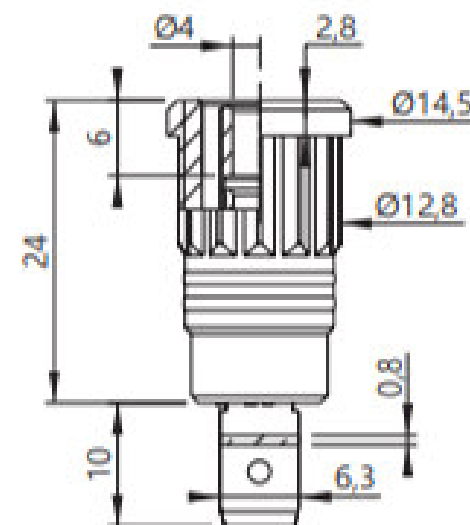

Rated voltage Tension assignée Bemessungsspannung	Rated current Intensité assignée Bemessungsstrom	Contact parts Contacts Kontaktteile	Insulation Isolant Isolierteile	Colours [#] Couleurs [#] Farben [#]
1000 V CAT III	36A	Brass / Ni coated (AuNi on request) Laiton / Revêtement Ni (AuNi sur demande) Messing vernickelt (AuNi auf Anfrage)	PA6.6	R N BL V J BC VT BN G J/V 2 0 6 5 4 9 7 1 8