

TYPE 3284


INSULATED MOUNTING RECEPTACLE Ø4MM PLUG / M6 THREADED
STUD + CABLE LUG, SURFACE MONTING
**EMBASE DE TERRE ISOLÉE FICHE Ø4MM / RACCORD FILETAGE
M6 + COSSE, MONTAGE EN SAILLIE**
**ISOLIERTE ERDUNGS- UND MASSEDOSE Ø4MM STECKER / M6
GEWINDEBOLZEN + KABELSCHUH, AUFBAUMONTAGE**

Reference
Référence
Bestell-Nr

3284-MD



Drilling • Perçage • Bohrung Ø8 ^{+0,1}₋₀

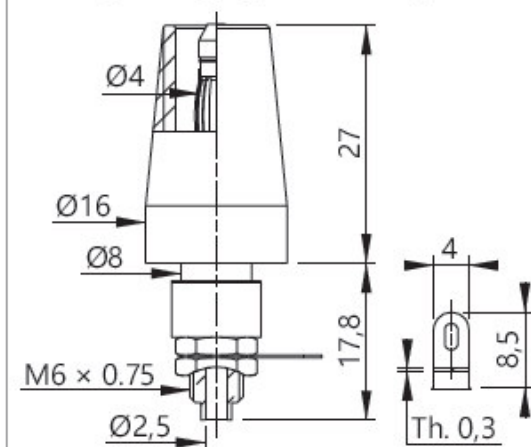

Rated voltage Tension assignée Bemessungsspannung	Rated current Intensité assignée Bemessungsstrom	Contact parts Contacts Kontaktteile	Insulation Isolant Isolierteile	Colours [#] Couleurs [#] Farben [#]
600 V CAT II	36A	Ni coated brass Laiton nickelé <i>Messing vernickelt</i>	PP	J/V 

This receptacle does not comply with our standard Ø4mm plugs
Cette embase n'est pas compatible avec nos fiches Ø4mm mâles standard
Diese Dose ist mit unseren Standard Ø4mm-Steckern nicht kompatibel