


TYPE 3295

Ø4MM SAFETY BANANA SOCKET / SOLDERING SLOT 1,6 MM /
PRESS FIT FIXING
DOUILLE DE SÉCURITÉ Ø4MM / RACCORD FOURCHE SOUDURE
1,6 MM / FIXATION PAR PRESSION
Ø4MM SICHERHEITS-EINBAUBUCHSE / 1,6 MM LÖTANSCHLUSS /
BEFESTIGUNG DURCH EIMPRESSEN

Reference
Référence
Bestell-Nr **3295-#**

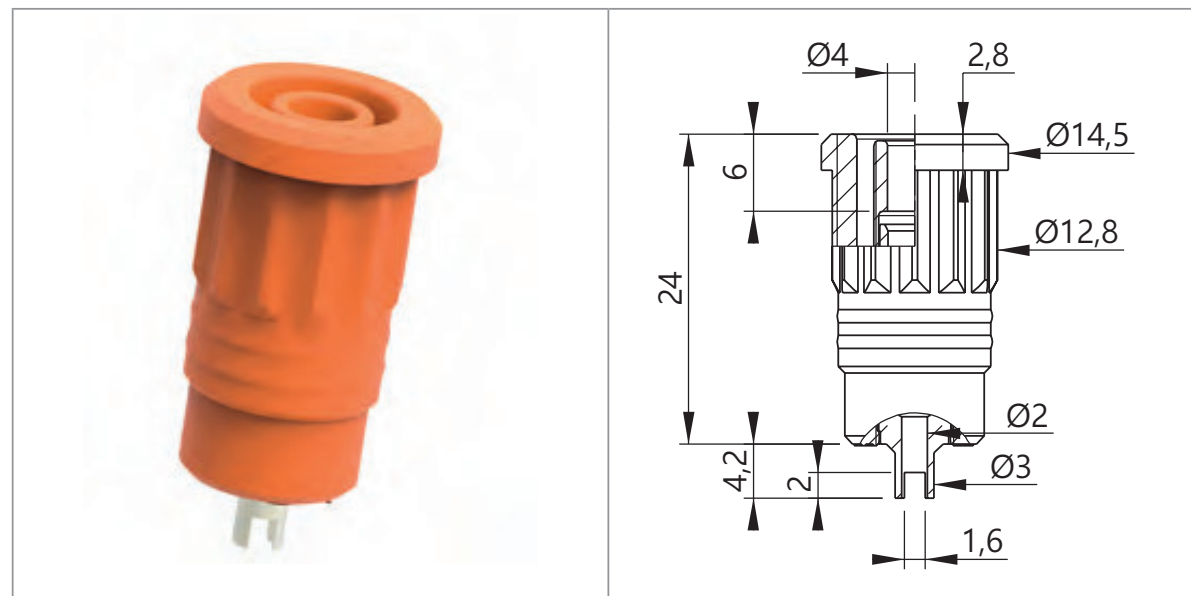

Rated voltage Tension assignée <i>Bemessungsspannung</i>	Rated current Intensité assignée <i>Bemessungsstrom</i>	Contact parts Contacts <i>Kontaktteile</i>	Insulation Isolant <i>Isolierteile</i>	Colours [#] Couleurs [#] <i>Farben [#]</i>
1000 V CAT III	25A	Brass / Ni coated (AuNi on request) Laiton / Revêtement Ni (AuNi sur demande) <i>Messing vernickelt (AuNi auf Anfrage)</i>	PA6.6	R N BL V J BC VT BN G J/V 2 0 6 5 4 9 7 1 8