
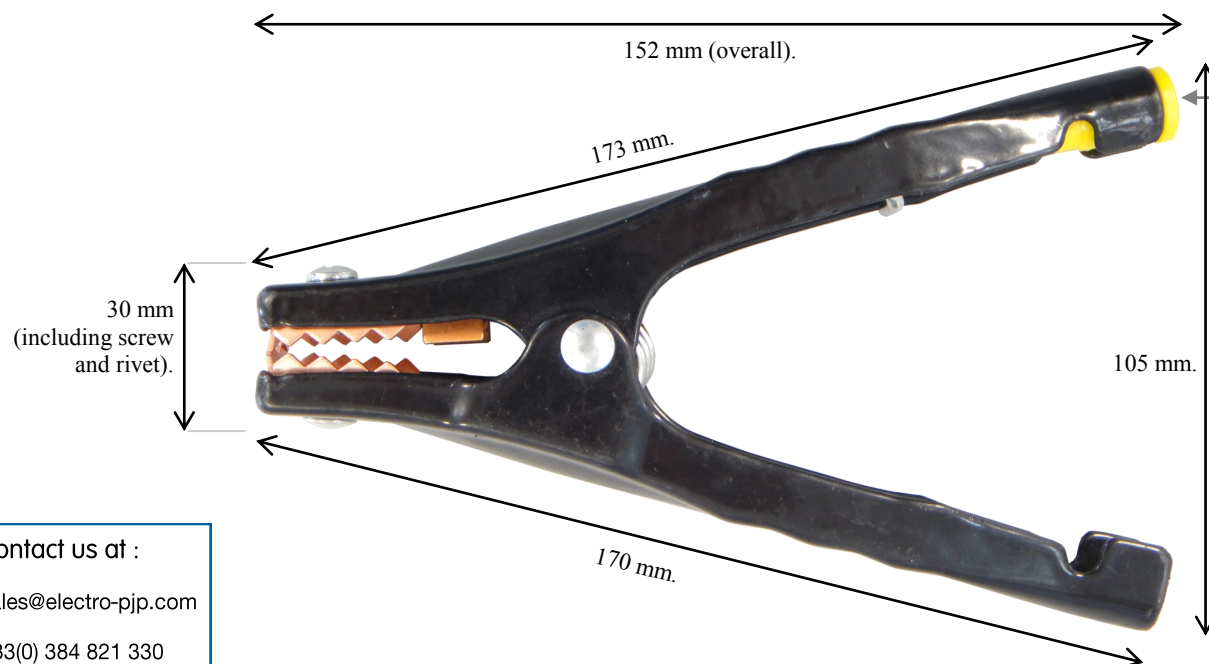
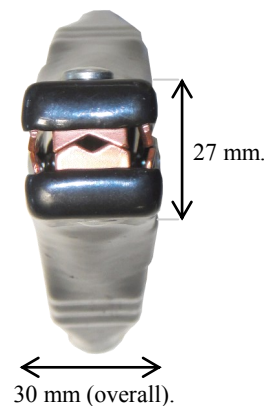


5064/3286

Designation : Big Alligator Clip w/ 4 mm Banana (female) Jack (socket).

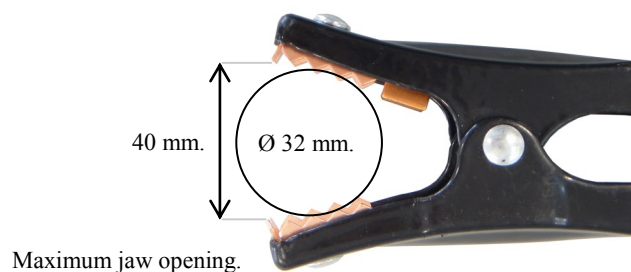

The 4 mm banana female connection complies with the 4 mm banana (shrouded and not shrouded) plugs of most of the worldwide most famous manufacturers and meets the requirements of interchangeability dimensions of the French standard NF C 93-440:1986.

Electrical protection	33 V AC / 70 V DC, 36 A (at 40 °C).
Operating temperature range	-20 °C mini., +80 °C maxi..
Materials	Conductors : copper-plated steel, nickel-plated brass, and steel. Insulators : epoxy and please contact us.
Colors	Main body Black Red Banana connection Black Red Yellow Green Blue White
Reliability benchmark	Year of 1st placing on the market 2009.
Packaging	Bag of 1 unit (default packaging).

Contact us at :

sales@electro-pjp.com

+33(0) 384 821 330