


TYPE 5270

Ø4MM SAFETY BANANA SOCKET WITH Ø14,5MM HEXAGONAL NUT / Ø2MM SOLDERING HOLE
TERMINAL

DOUILLE DE SÉCURITÉ Ø4MM AVEC ÉCROU HEXAGONAL Ø14,5MM / RACCORD TROU Ø2MM
Ø4MM SICHERHEITS-EINBAUBUCHSE MIT Ø14,5MM SECHSKANTMUTTER / Ø2MM
LÖTANSCHLUSS

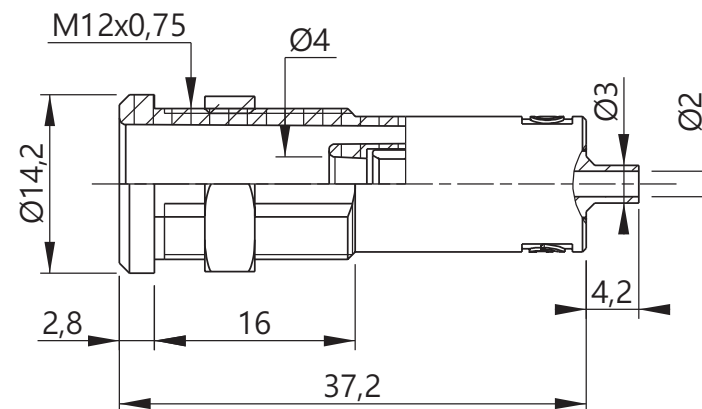

Reference Référence Bestell.-Nr.	Rated voltage Tension assignée Bemessungsspannung	Rated current Intensité assignée Bemessungsstrom	Contact parts Contacts Kontaktteile	Insulation Isolant Isolierteile	Colours [#] Couleurs [#] Farben [#]
5270-C-HT-#	5000 V CAT 0 (Transient overvoltage 2 kV) 5000 V CAT 0 (Surtensions transitoires 2kV) 5000 V CAT 0 (Transiente Überspannungen 2 kV)	10A	Ni coated brass Laiton nickelé Messing vernickelt	PP	R N 2 0
5270-I-HT-#	5000 V CAT 0 (Transient overvoltage 2 kV) 5000 V CAT 0 (Surtensions transitoires 2kV) 5000 V CAT 0 (Transiente Überspannungen 2 kV)	10A	Ni coated brass Laiton nickelé Messing vernickelt	PP	