


Ada32/1,4

TEST POINT, SMOOTH PIN Ø1,4MM (L = 13MM) / Ø4MM FEMALE
POINTE TEST, TIGE LISSE Ø1,4 (L = 13M) / FEMELLE Ø4MM
PRÜFSPITZE, GLATTER STIFT Ø1,4MM (L = 13MM) / Ø4MM BUCHSE

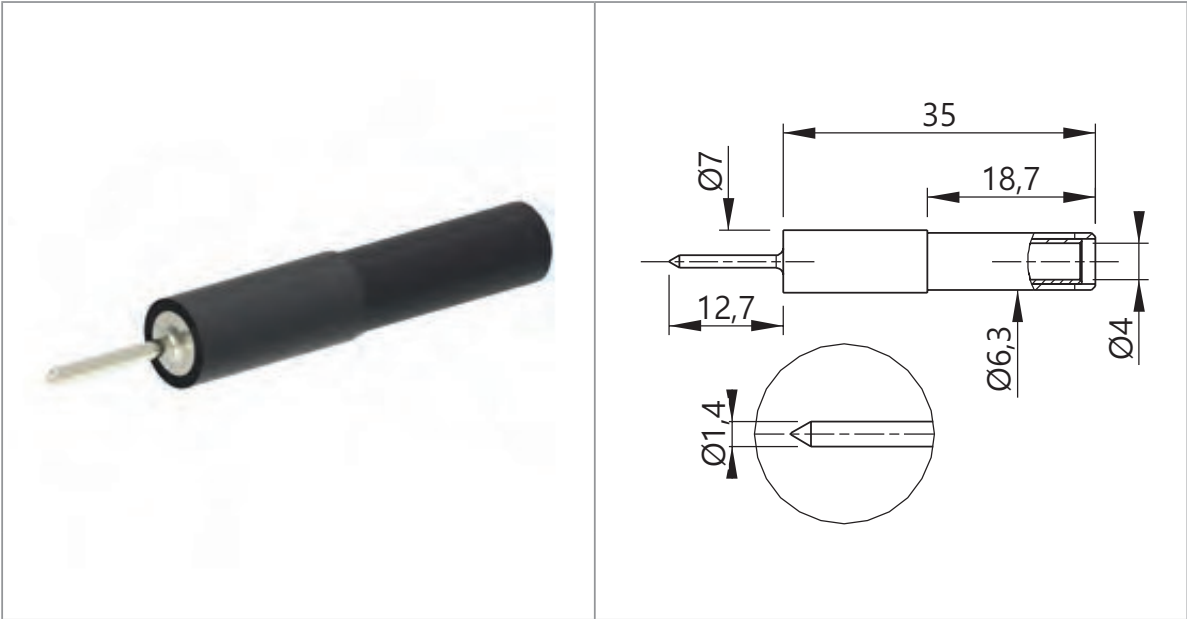

Reference
Référence | Ada32/1.4-#
Bestell-Nr

Rated voltage Tension assignée <i>Bemessungsspannung</i>	Rated current Intensité assignée <i>Bemessungsstrom</i>	Contact parts Contacts <i>Kontaktteile</i>	Insulation Isolant <i>Isolierteile</i>	Colours [#] Couleurs [#] <i>Farben [#]</i>
≤30VAC ≤60VDC	36A	Ni coated brass Laiton nickelé <i>Messing vernickelt</i>	PA6	R 2 N 0 BL 6 V 5 J 4 BC 9