


ORDER CODE	TIP	OUTER SHEATH (Ø MM)	BUFFER (µM)	ACRYLATE (µM)	FIBER OPTIC (MM - µM)	WEIGHT (G)	LENGTH (MM)	NOTES
CS-KC		-	-	-	-	80g	145mm	Kevlar cutter
CSF-1		-	-	-	max 0.5mm	83g	145mm	Adjustable single hole wire stripper (max 0.5mm)
CSF-1-125		-	-	250µm	125µm	83g	145mm	Pre-calibrated fiber optic wire stripper (125 micron)
CSF-3		Ø 1.6-3mm	600-900µm	250µm	125µm	83g	145mm	Pre-calibrated 3 holes fiber optic wire stripper
K2-1		-	-	-	-	200g	200x100x30mm	Optical fiber tools belt pouch
SC6/8		-	-	-	6.0-8.0mm	130g	170mm	Cable stripper for Minibreakout
SC6/8-K	-	-	-	-	-	-	-	Spare kit for SC6/8


ORDER CODE	TIP	WEIGHT (G)	LENGTH (MM)
------------	-----	------------	-------------

CS-KC

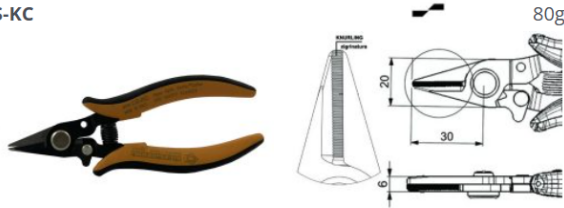

Kevlar cutter.
Ergonomic bi-material handles for a better grip. Anti-reflection and anti-oxidation surface treatment (phosphate coating). Closing stop lever. Steel thickness 3mm. Grip model S.


CSF-1

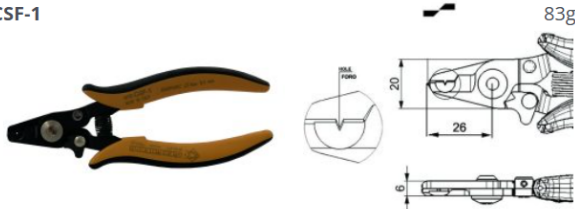

Adjustable single-holes fiber optic wire stripper (max 0.5mm).
Ergonomic bi-material handles for a better grip. Anti-reflection and anti-oxidation surface treatment (phosphate coating). Closing stop lever. Steel thickness 3mm. Grip model S.

ORDER CODE	TIP	WEIGHT (G)	LENGTH (MM)
------------	-----	------------	-------------

CSF-1-125

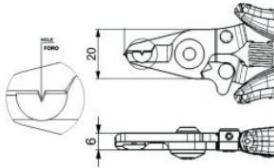


83g

145mm

Pre-calibrated single-holes fiber optic wire stripper (125µm).
Ergonomic bi-material handles for a better grip. Anti-reflection and anti-oxidation surface treatment (phosphate coating). Closing stop lever. Steel thickness 3mm. Grip model S.

CSF-3

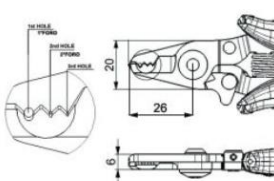

83g

145mm

Pre-calibrated 3-holes wire stripper to remove fiber optic coating in one tool.
1st hole: from 1.6 to 3mm (outer sheath)
2nd hole: from 600 to 900 micron (buffer)
3rd hole: from 250 micron (acrylate)
Ergonomic bi-material handles for a better grip. Anti-reflection and anti-oxidation surface treatment (phosphate coating). Closing stop lever. Steel thickness 3mm. Grip model S.

ORDER CODE	TIP	WEIGHT (G)	LENGTH (MM)
------------	-----	------------	-------------

SC6/8



130g

170mm

Cable stripper for Minibreakout. This cable stripper is used to create a longitudinal window cut on vertical FTTH cables. In this way the operator can access the fiber modules inside the cable.
- suitable for cables 6-8mm diameters
- interchangeable steel blades

Hardened steel. Ergonomic bi-material handles for a better grip. Closing stop lever.
Anti-reflection and anti-oxidation surface treatment (phosphate coating).

Available the spare kit for SC6/8 (order code SC6/8-K).

SC6/8-K



-

-

Spare kit for SC-6/8 cable stripper.
It composed of:
- no. 4 blades
- no. 1 pin Ø 1x25mm
- no. 1 hexagonal wrench.