

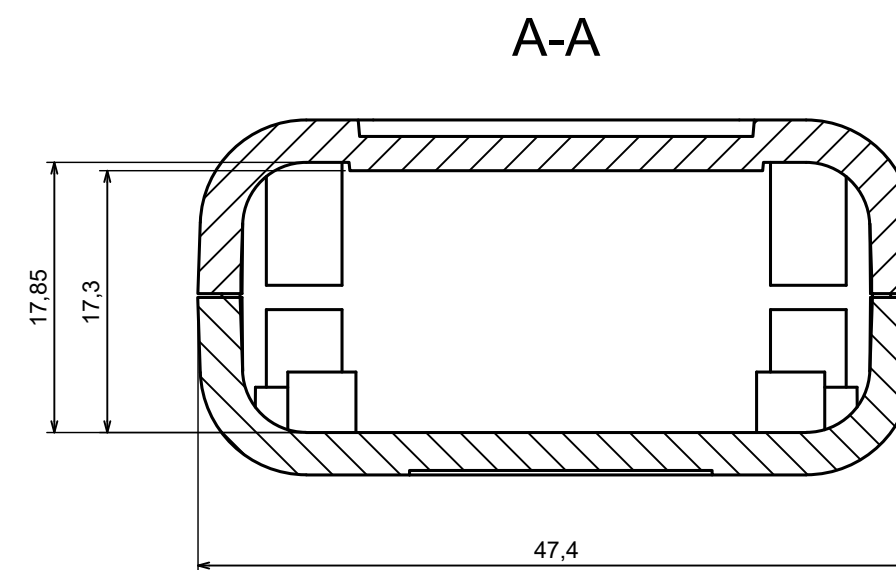
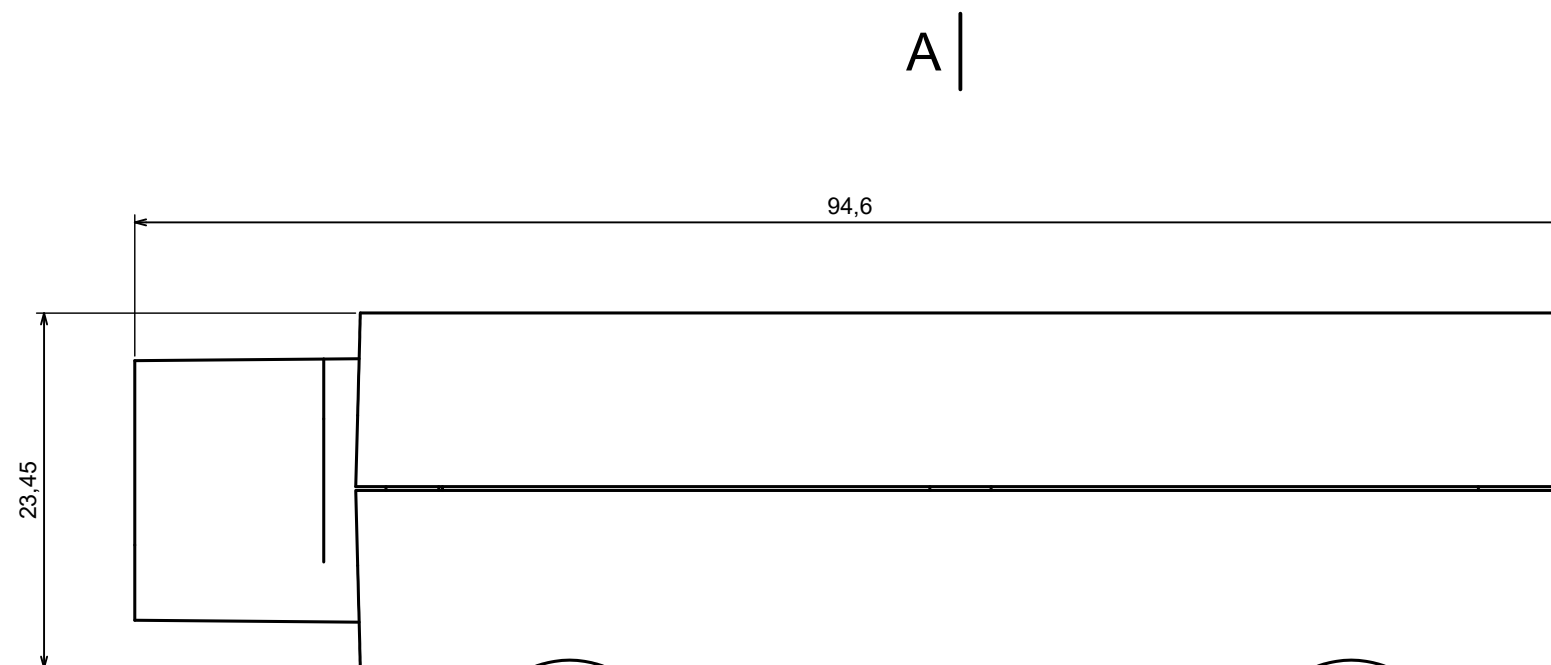
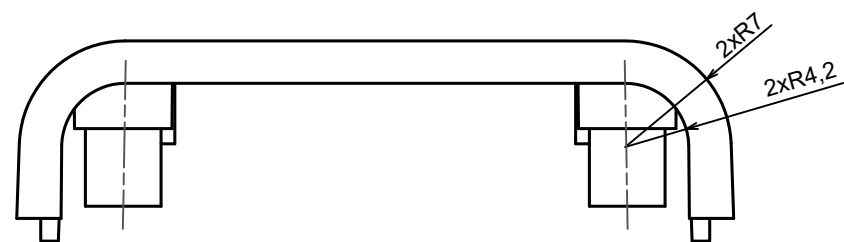
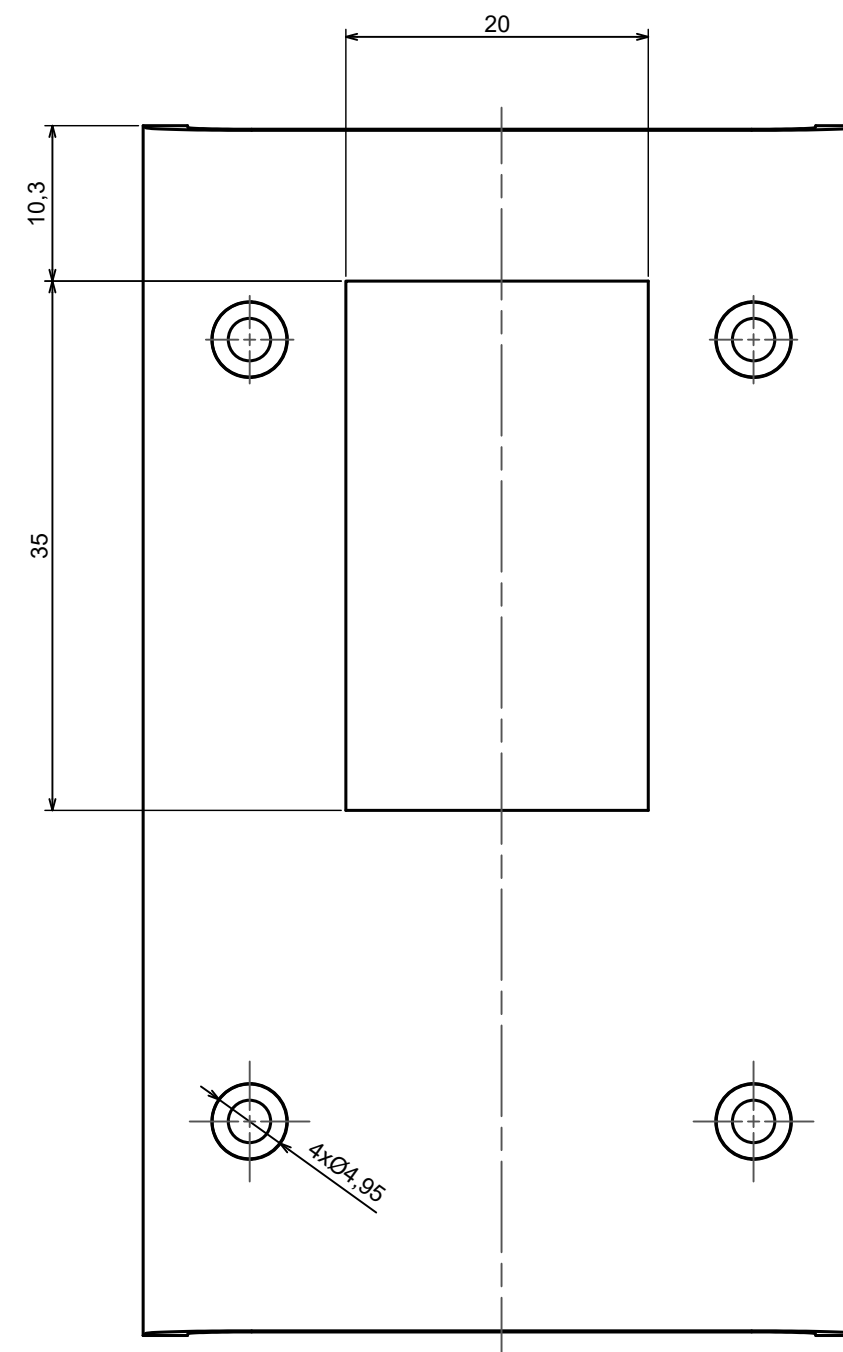


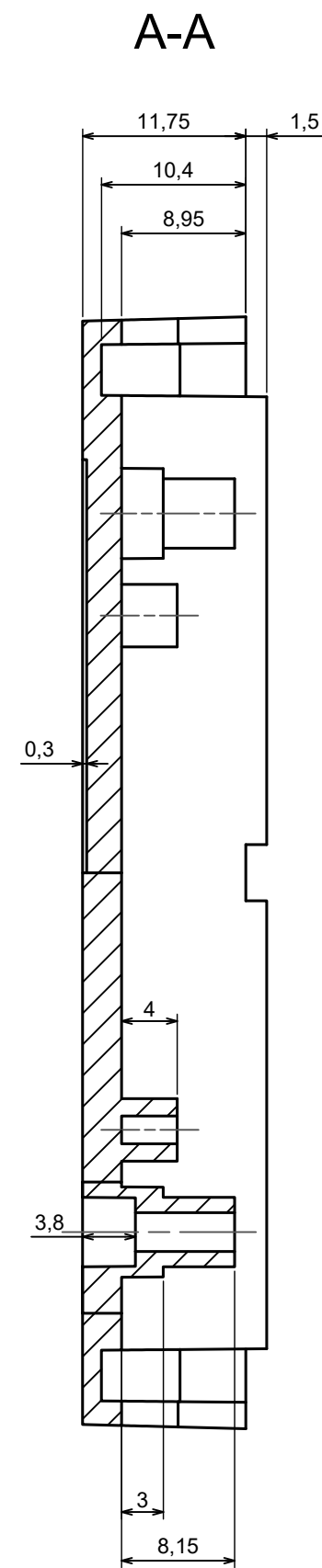

All rights reserved, Copyright Kradex 2025		
Product model	ZOBD SET 24V - Assembly	
Format: A3	Material: ABS	
Scale 2:1	Tolerance: +/- 0.5	

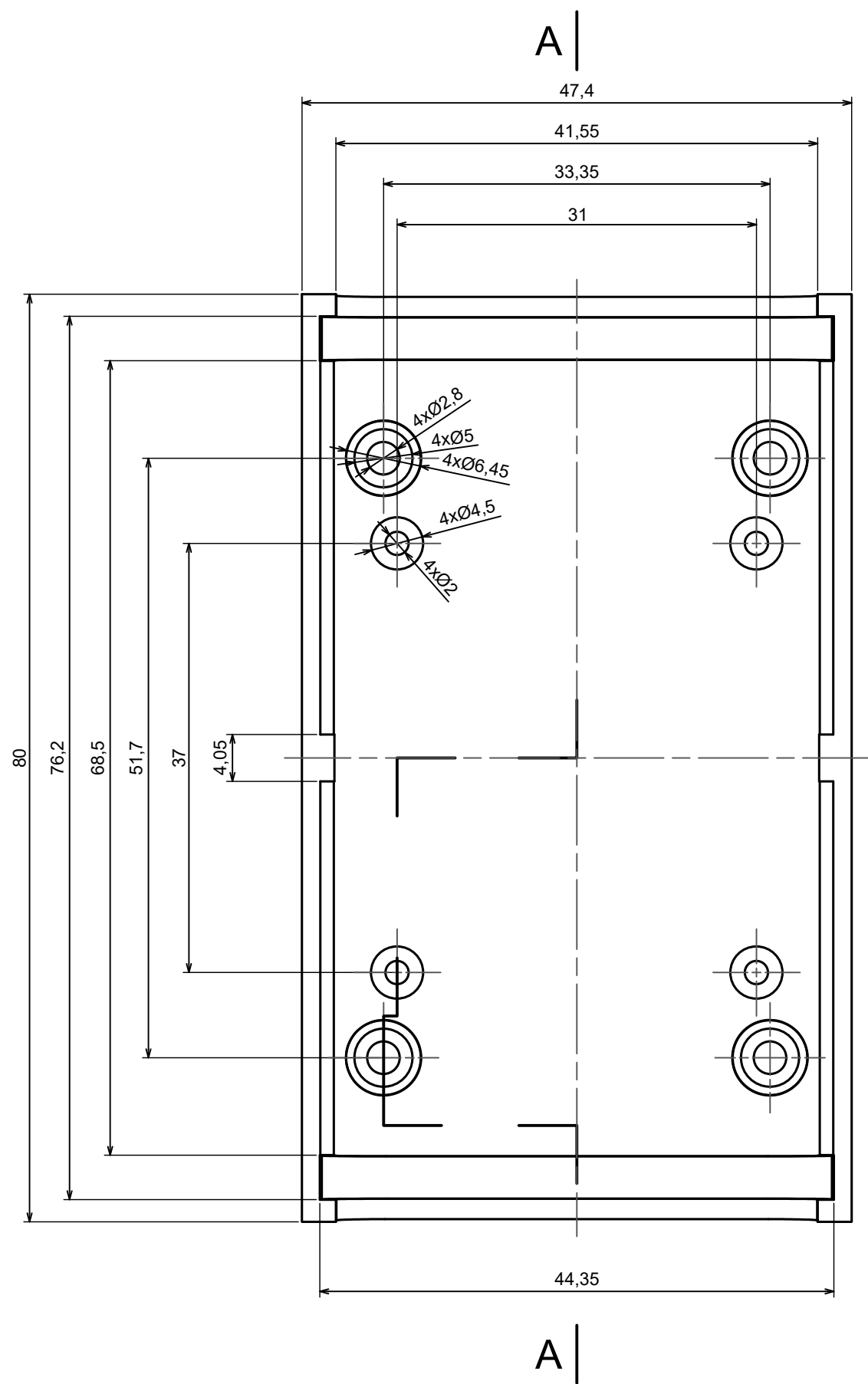





All rights reserved, Copyright Kradex 2025

Product model ZOBD - Base



Format: A3 Material: ABS

Scale 2:1 Tolerance: +/- 0.5







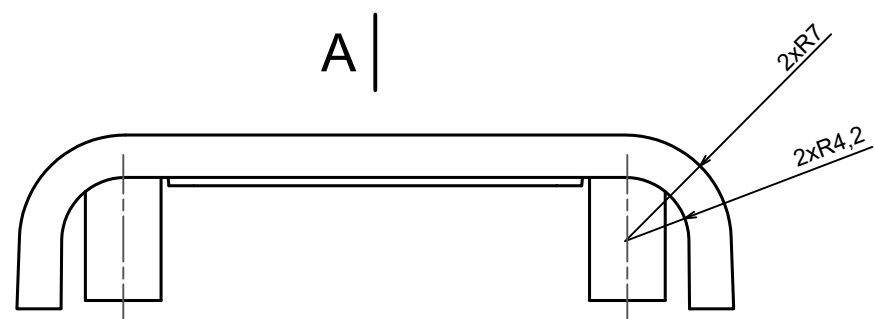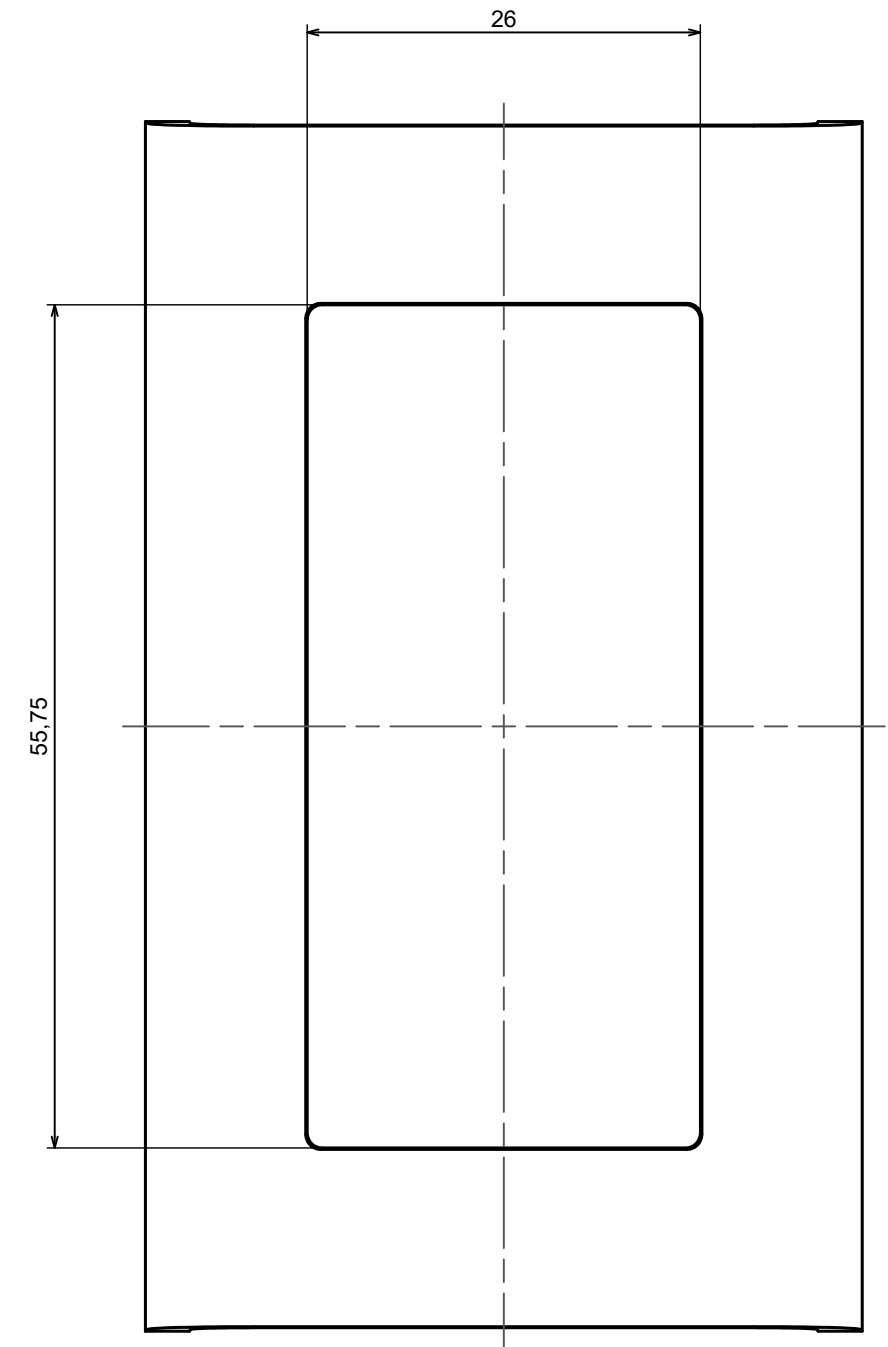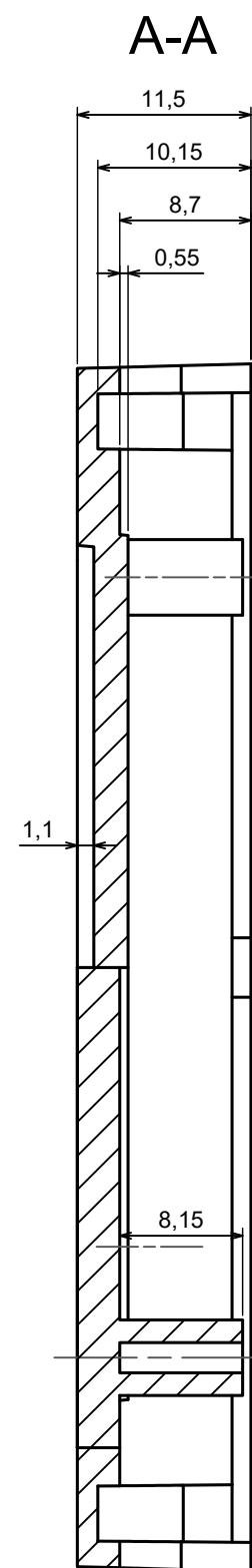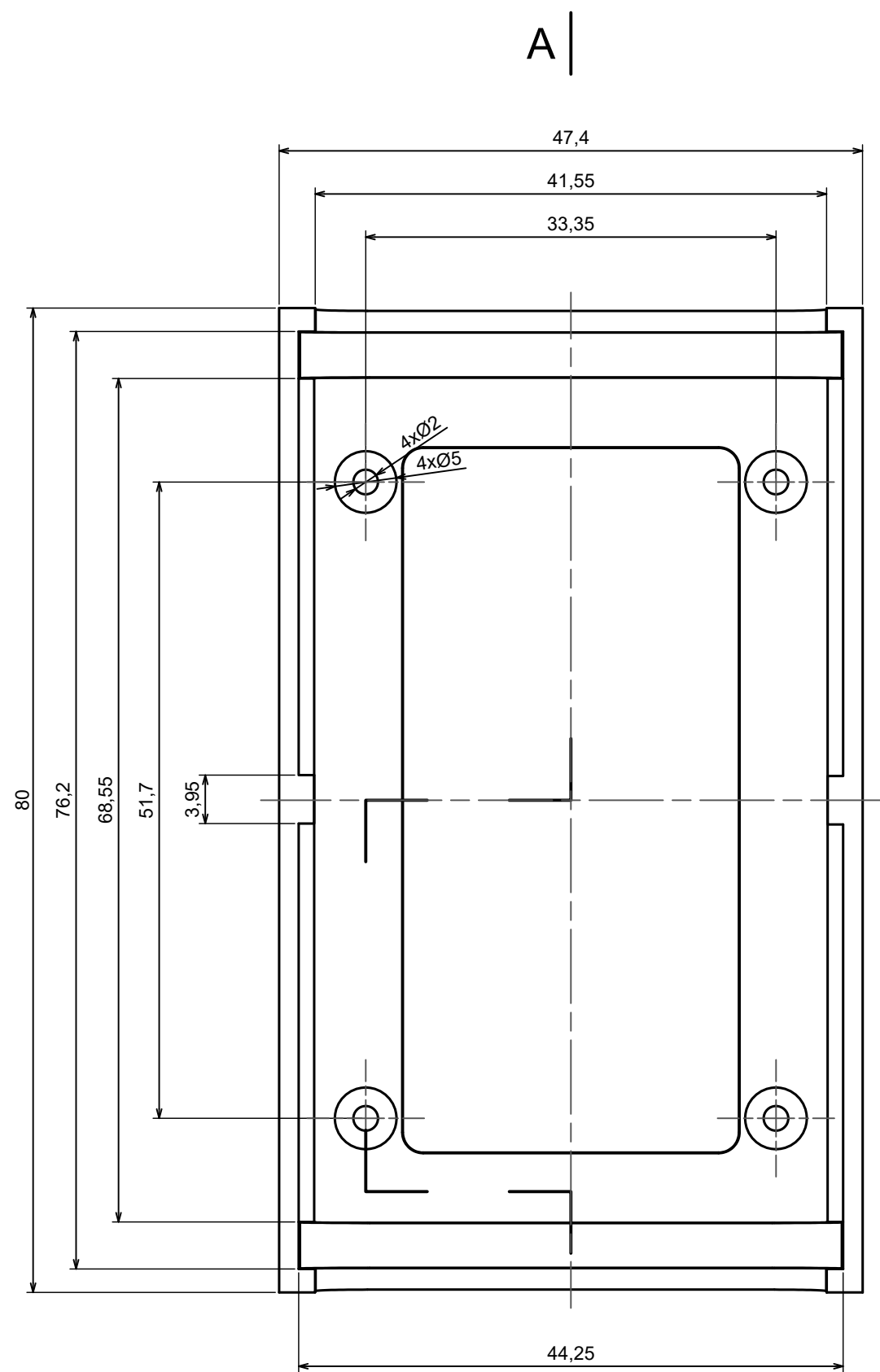

All rights reserved, Copyright Kradex 2025		
Product model	ZOBD - Cover	
Format: A3	Material: ABS	
Scale 2:1	Tolerance: +/- 0.5	

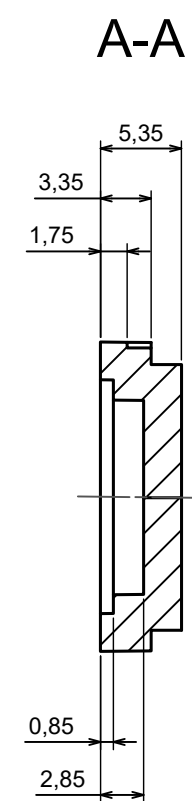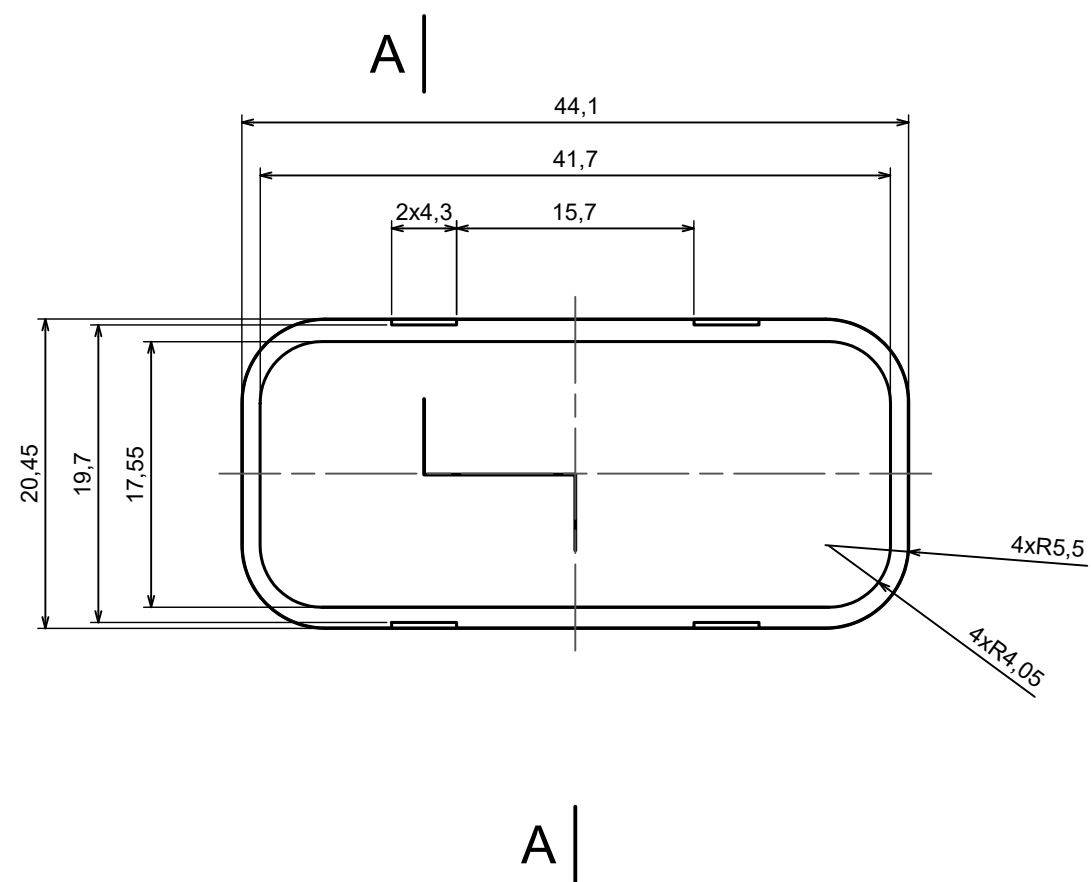

All rights reserved, Copyright Kradex 2025		
Product model	ZOBD CAP	
Format: A3	Material: ABS	
Scale 2:1	Tolerance: +/- 0.5	

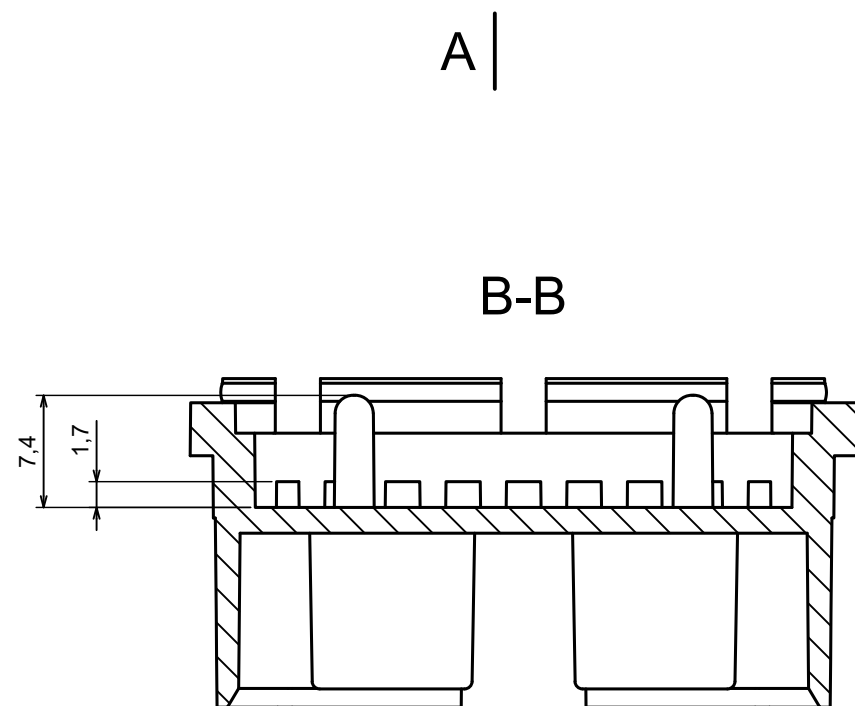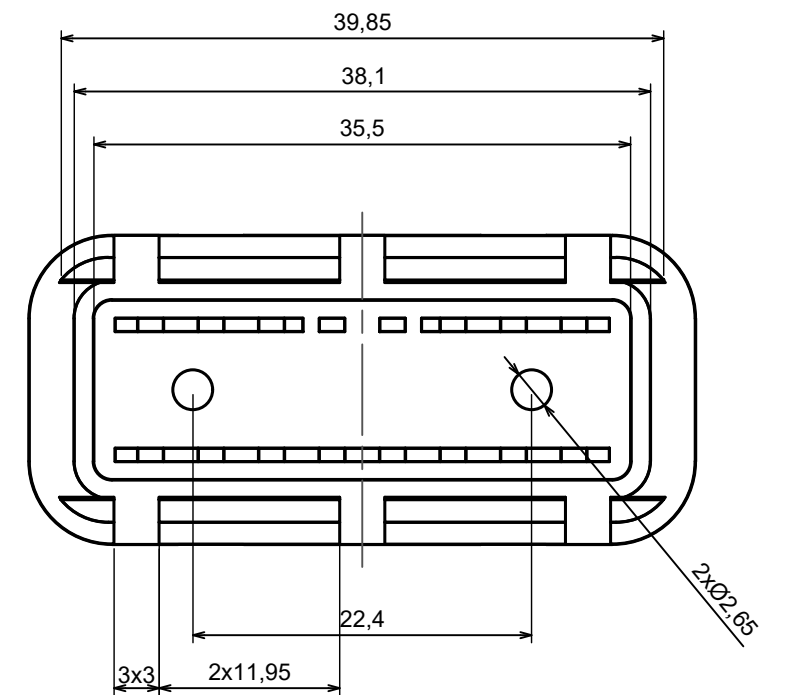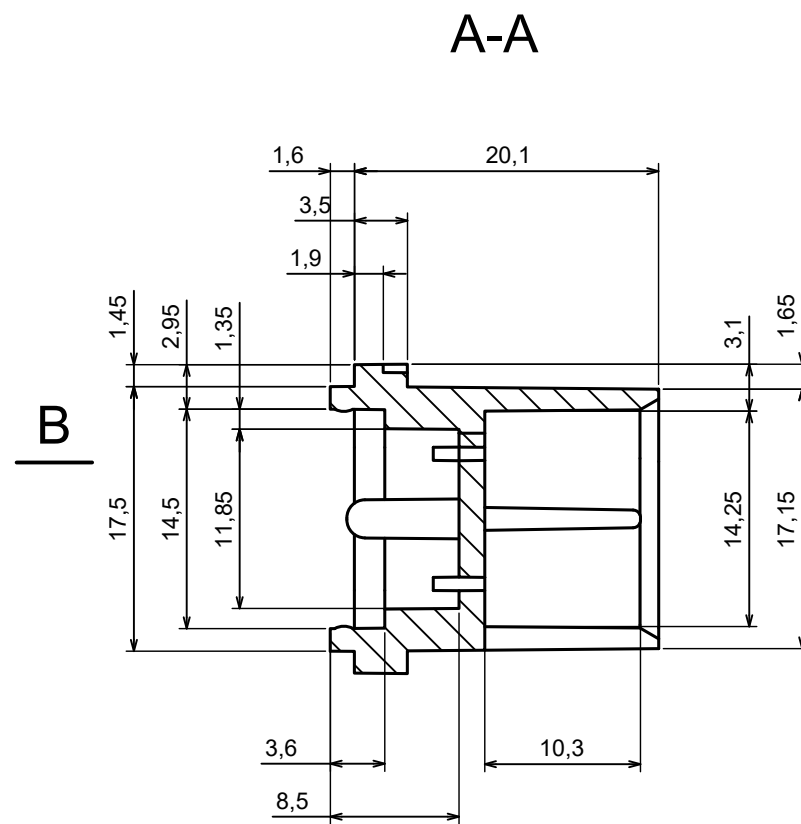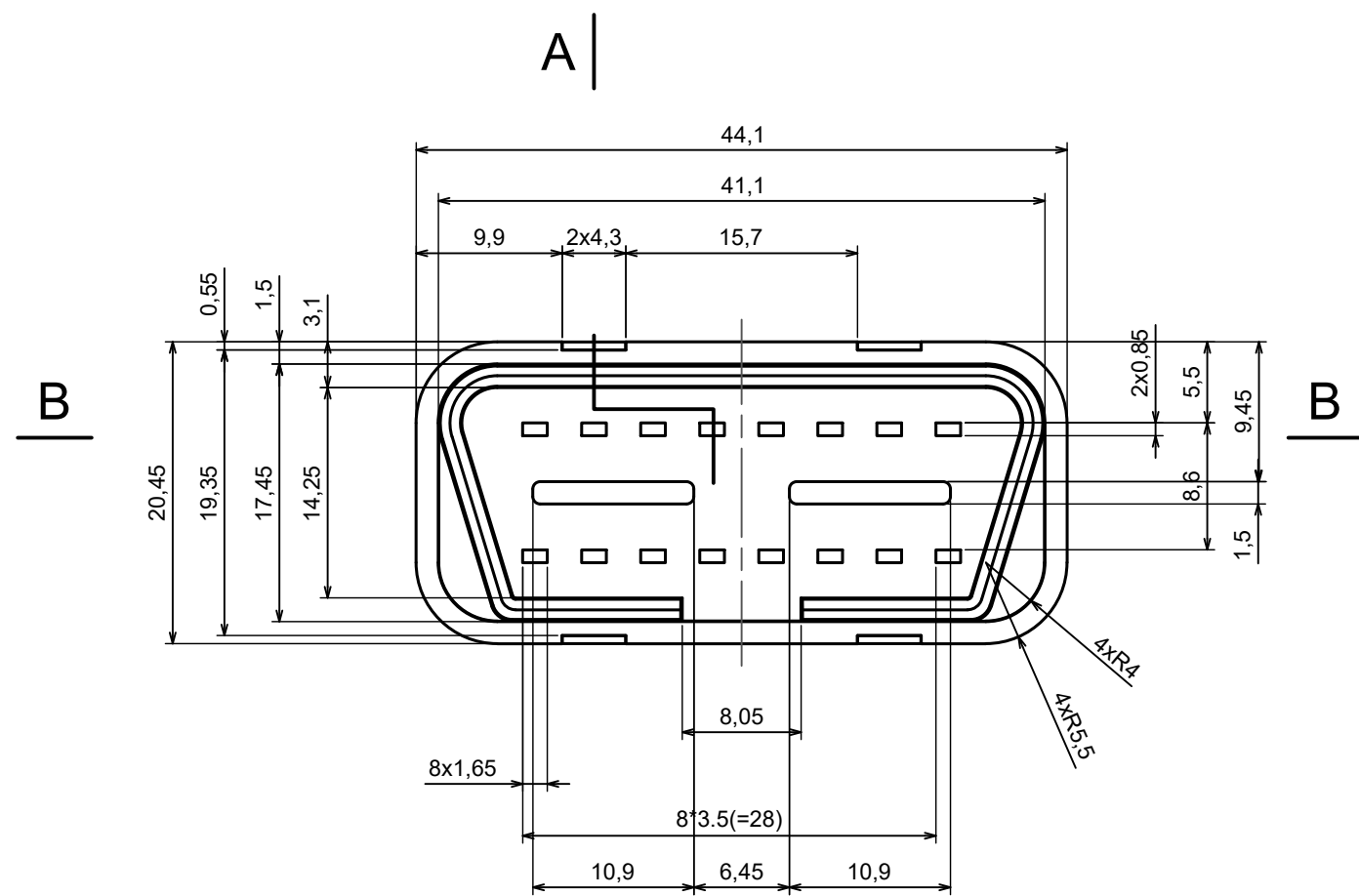



All rights reserved, Copyright Kradex 2025

Product model ZOBD CAP PLUG 24V


Format: A3 Material: ABS

Scale 2:1 Tolerance: +/- 0.5



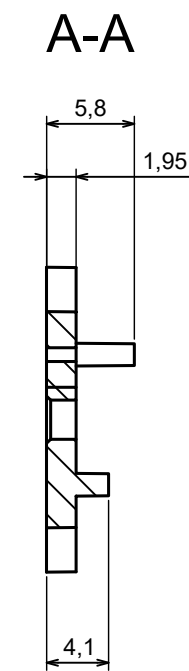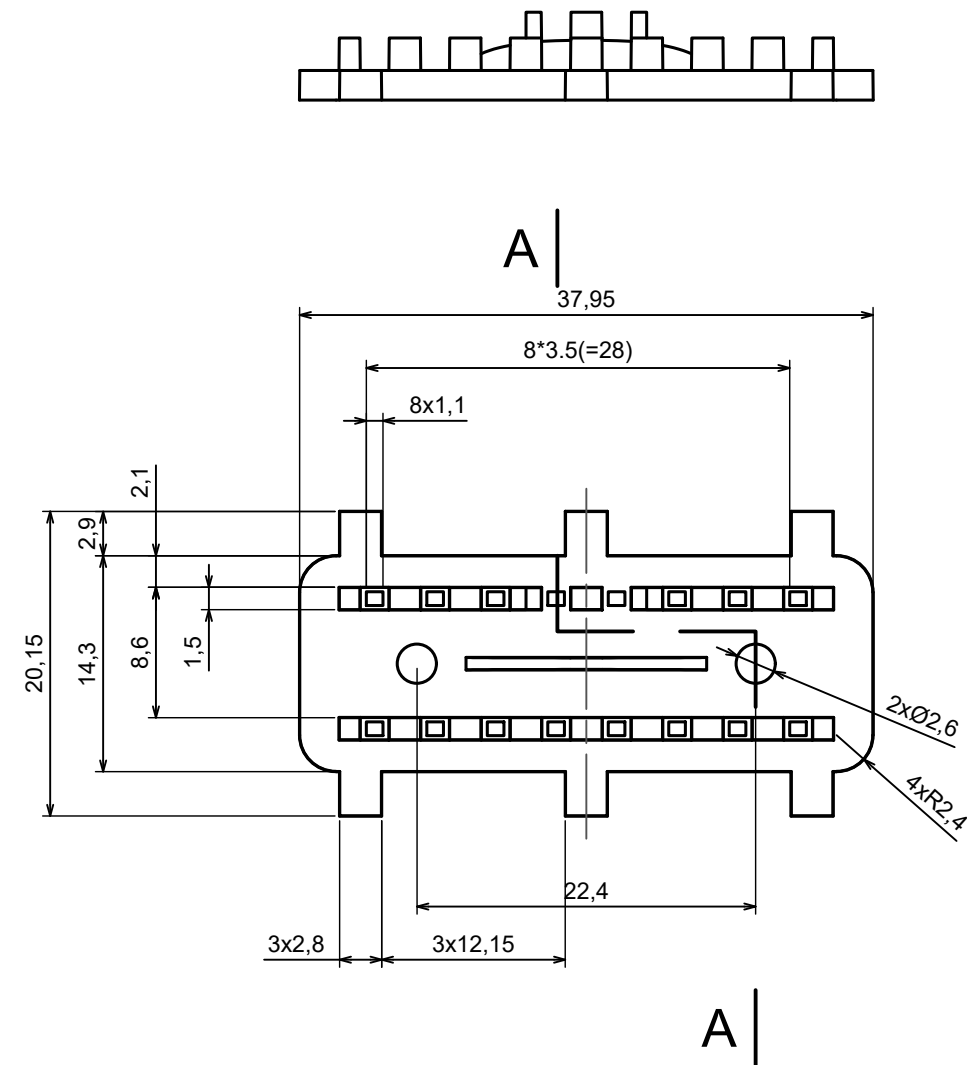

All rights reserved, Copyright Kradex 2025		
Product model	ZOB CAP PLUG 24V CAP	
Format: A3	Material: ABS	
Scale 2:1	Tolerance: +/- 0.5	

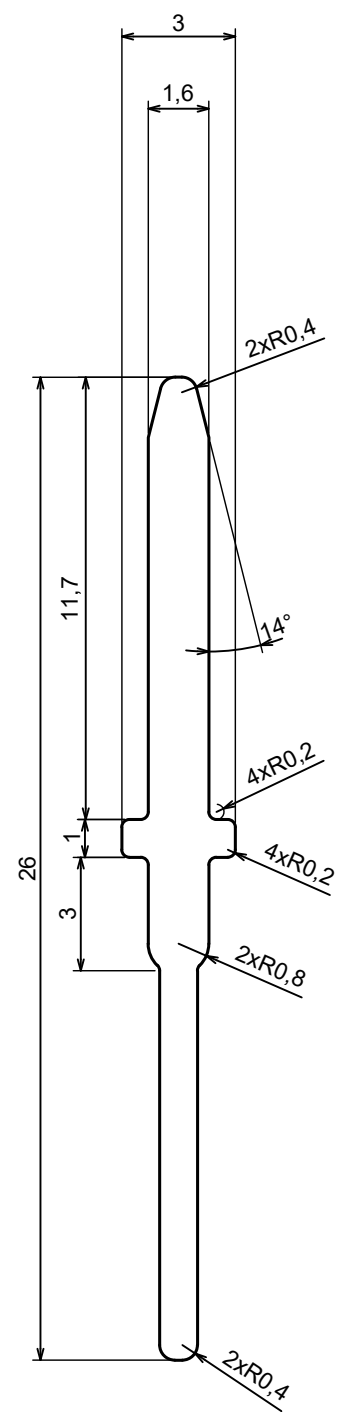

All rights reserved, Copyright Kradex 2025		
Product model	ZOBD SET PIN	
Format: A3	Material: b6z6	
Scale 2:1	Tolerance: +/- 0.5	