

HDC 04A DODL 1LB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Version	HDC enclosures, Size: 1, Protection degree: IP65, in plugged condition, Cover for upper part of housing, Side-locking clamp on lower side, Standard
Order No.	1963690000
Type	HDC 04A DODL 1LB
GTIN (EAN)	4032248645961
Qty.	1 pc(s).

HDC 04A DODL 1LB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	25 mm	Height (inches)	0.984 inch
Width	36.5 mm	Width (inches)	1.437 inch
Net weight	30 g		

Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

Dimensions

Cable entry	with male	Height of housing B	18 mm
Total length housing	31 mm	Width housing C	26.8 mm

General data

EMC housings	No	Housing main material	diecast aluminium
Material of locking element	Stainless steel, rust-proof	Protection degree	IP65, in plugged condition
Surface finish	Powder coating	Tightening torque	0.5 Nm

Version

BG	1	Cable entry	with male
Clamp version	Side-locking clamp	Colour (RAL)	RAL 7035
Cover	without cover	Design	Standard
Design of housing	Cover for upper part of housing	Design of locking system	Side-locking clamp on lower side
Size	1	Suitable for ModuPlug®	No
Tightening torque	0.5 Nm	Top part/bottom part/lid	Cover

Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ETIM 10.0	EC000437	ECLASS 9.0	27-44-02-02
ECLASS 9.1	27-44-02-02	ECLASS 10.0	27-44-02-02
ECLASS 11.0	27-44-02-02	ECLASS 12.0	27-44-02-02
ECLASS 13.0	27-44-02-02	ECLASS 14.0	27-44-02-02
ECLASS 15.0	27-44-02-02		

Approvals

ROHS	Conform
------	---------

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant

Creation date July 15, 2025 2:38:55 PM CEST

Catalogue status 04.07.2025 / We reserve the right to make technical changes.

HDC 04A DODL 1LB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Substance	Transmission oil
Chemical resistance	Resistant
Substance	Hydraulic oil
Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%
Chemical resistance	de.myview.objectmodel.impl.BlockImpl@3a572dd3 de.myview.objectmodel.impl.BlockImpl@2d46a5d7 de.myview.objectmodel.impl.BlockImpl@572a7b42 de.myview.objectmodel.impl.BlockImpl@3fdb4adc de.myview.objectmodel.impl.BlockImpl@3ce1d141 de.myview.objectmodel.impl.BlockImpl@2411b317 de.myview.objectmodel.impl.BlockImpl@20652cbc de.myview.objectmodel.impl.BlockImpl@458d1fc6 de.myview.objectmodel.impl.BlockImpl@7754b5ef de.myview.objectmodel.impl.BlockImpl@5e743919 de.myview.objectmodel.impl.BlockImpl@57fdeea7 de.myview.objectmodel.impl.BlockImpl@7a23b8b1 de.myview.objectmodel.impl.BlockImpl@280a91d7

Downloads


Engineering Data	CAD data – STEP
Product Change Notification	20220214 Technical change to HDC housings 20220214 Technische Änderung bei HDC-Gehäusen
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN FL FIELDWIRING EN

HDC 04A DODL 1LB

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

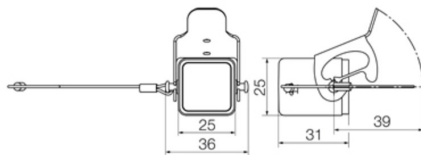

HDC 04A DODL 1LB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Plug enclosure, cable entry sideways



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 04A TWLU 1M20G	Version
Order No.	1788810000	HDC enclosures, Size: 1, Protection degree: IP65, in plugged condition, Cable entry from side, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 20
GTIN (EAN)	4032248206353	
Qty.	1 pc(s).	
Type	HDC 04A TWLU 1PG11G	Version
Order No.	1652480000	HDC enclosures, Size: 1, Protection degree: IP65, in plugged condition, Cable entry from side, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 11
GTIN (EAN)	4008190402556	
Qty.	1 pc(s).	

Plug enclosure, cable entry at top



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 04A TOLU 1M16G	Version
Order No.	1206090000	HDC enclosures, Size: 1, Protection degree: IP65, in plugged condition, Cable entry from top, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 16
GTIN (EAN)	4050118027587	
Qty.	1 pc(s).	

HDC 04A DODL 1LB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories**

Type	HDC 04A TOLU 1PG11G	Version
Order No.	1652470000	HDC enclosures, Size: 1, Protection degree: IP65, in plugged
GTIN (EAN)	4008190402549	condition, Cable entry from top, Plug housing, Side-locking clamp on
Qty.	1 pc(s).	lower side, Standard, Size of cable entries: PG 11
Type	HDC 04A TOLU 1M20G	Version
Order No.	1788820000	HDC enclosures, Size: 1, Protection degree: IP65, in plugged
GTIN (EAN)	4032248206360	condition, Cable entry from top, Plug housing, Side-locking clamp on
Qty.	1 pc(s).	lower side, Standard, Size of cable entries: M 20