


MP22DMPINRR110A5 Datasheet

Product Name // MP22DMPINRR110A5 Power Symbol  
Illumination Vandal Resistant Switch

 [View Product Page](#)

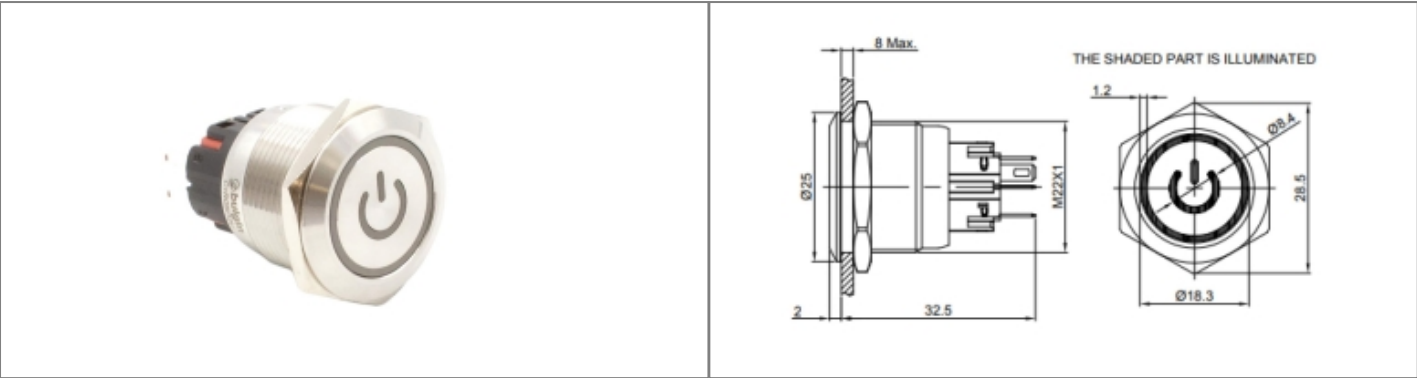

// Product Description:

- MP22 Range
  - DPDT
  - Momentary
  - Power Symbol Illumination
- Red
  - 110V
  - AL alloy Black
  - IP65

// General Information:

|                                  |                                                   |
|----------------------------------|---------------------------------------------------|
| Product Display Title:           | Power Symbol Illumination Vandal Resistant Switch |
| Product Family:                  | Switch Range                                      |
| Product Series:                  | Vandal Resistant Switches                         |
| Bezel Finish:                    | Gloss                                             |
| Body Colour:                     | Black                                             |
| Body Material:                   | Aluminium                                         |
| Body Material Type:              | Metal                                             |
| Current Rating:                  | 5A 250V                                           |
| Diameter:                        | 22mm                                              |
| Dielectric Withstanding Voltage: | 1500V                                             |
| Durability:                      | 50,000                                            |
| Function:                        | Push Button Switch                                |
| Illumination Colour:             | Red                                               |
| Illumination Shape:              | Power Symbol                                      |
| Illumination Voltage:            | 110V                                              |
| Ip Rating:                       | IP65                                              |
| Lamp Type:                       | LED                                               |
| Material Finish:                 | Gloss                                             |
| Max Operating Temperature:       | 55°C                                              |
| Min Operating Temperature:       | -25°C                                             |
| Max Panel Thickness:             | 8mm                                               |
| Operating Humidity:              | 45~85 RH(Non condensing)                          |
| Panel Cut Out:                   | 22mm Diameter circle                              |
| Rohs Compliant:                  | Yes                                               |
| Switch Body Colour:              | Black                                             |
| Switch Body Material:            | Aluminium                                         |
| Switch Button Colour:            | Black                                             |
| Switch Button Material:          | Aluminium                                         |
| Switch Circuit:                  | DPDT                                              |
| Switch Series:                   | MP22                                              |
| Switch Shape:                    | Round                                             |
| Switch Type:                     | Pushbutton                                        |
| Switching Type:                  | Momentary                                         |
| Thread Size:                     | M22                                               |

// Product PDF Links

 [22mm Vandal Resistant Switch](#)

// Product 3D CAD Model Links

 [MP22DMPINRR110A53D CAD Model](#)



Have a question or project enquiry  
you'd like to talk to us about?



[Click Here To Contact Us](#)