
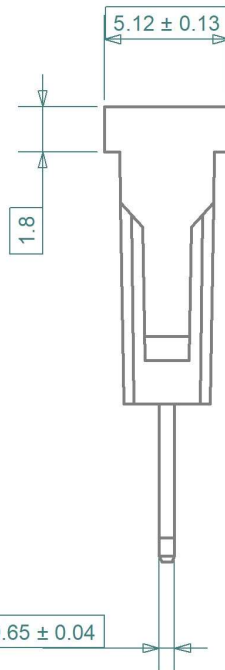


A

 
B

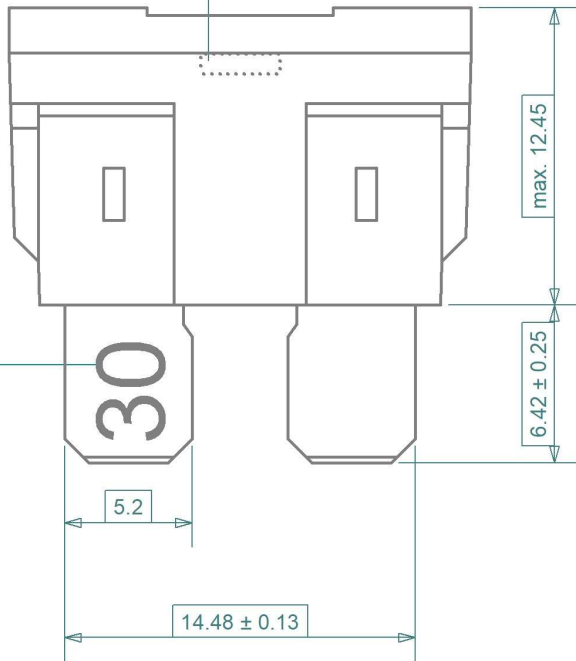

Rating [A]	Color	Volt [V]	iMaXX Reference
3	Violet	32	F1903
4	Pink	32	F1904
5	Tan	32	F1905
7.5	Brown	32	F1975
10	Red	32	F1910
15	Blue	32	F1915
20	Yellow	32	F1920
25	Natural	32	F1925
30	Green	32	F1930

Notes	
A	LED / PCB placement
B	Amperage rating printed on fuse body
C	Amperage rating stamped
*	Fuse series for after market use

Fusing time SAE J-1284 [s]		
Load [%]	Minimum [s]	Maximum [s]
110 %	360,000	-
135 %	0.75	1,800
200 %	0.15	5
350 %	> 0.08	

Revisions				Date	Appr.		
	Date	Type	Drawn	12/08	GRH		
a	08/11	rating print on top added	Checked	04/24	EB		
b	10/12	updated dimensions	Standards				
c	04/24	added note	Approved	04/24	AdH		
			Scale	Not to scale		Title	F1900 series, ShoBlo normOTO blade fuse
			Projection	Tolerance ± 0.2 mm unless otherwise noted		Drawing type	schematic
						Drawing number	F1900 (LED) drawing 1
						Sheet	1 of 1
						Layers / Sheet	0 1 2 6 9 Sheet 01